

Indicator element

84-8001.3620



<https://eao.com/p/84-8001.3620>

Your product:



84-8001.3620

Indicator element

OPERATING-/INDICATION PART

Illumination colour: Amber

ELECTRICAL CHARACTERISTICS

Operating voltage: 24 V DC $\pm 10\%$

Lumi. Intensity: mcd

MECHANICAL CHARACTERISTIC

Terminal: Plug-in terminal, 2.8 x 0.8 mm

Weight: 0.005 kg

AMBIENT CONDITION

IP Protection: IP40

CERTIFICATE

REACH: REACH compliant

RoHS: RoHS compliant

OTHER


Short Description: Indicator element, Amber, Single-LED, 24 V DC $\pm 10\%$, Plug-in terminal, 2.8 x 0.8 mm

Kind of illumination: Single-LED





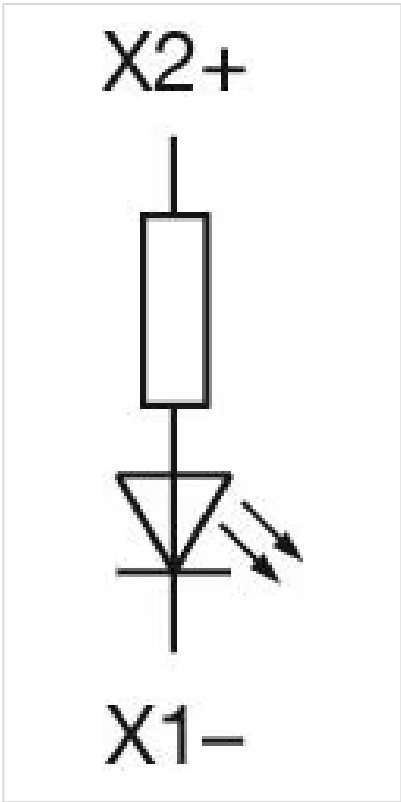

Hints: LED and built-in resistor included, Standard version: Cable length 300 mm, Other options on request: Customisation of cable and connectors, rear side fully sealed (IP 67), Protection degree (rear side): IP 40, upgrade to IP 67 with plug Part No. 84-

900 possible. With applications where strong vibrations occur, the plugs may become loose, Luminosity and wave length variations caused by LED manufacturing processes may cause slight differences regarding the illumination. The customer has to decide what resistor shall be used to the LED

Wiring diagrams:



Where to Buy

Distributor		Quantity in Stock		
	DigiKey	8 in stock	Buy	
	Mouser Electronics	0 in stock	Buy	
	RS Americas	0 in stock	Buy	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[84-8001.3620](#)