


Indicator element

84-8001.3640

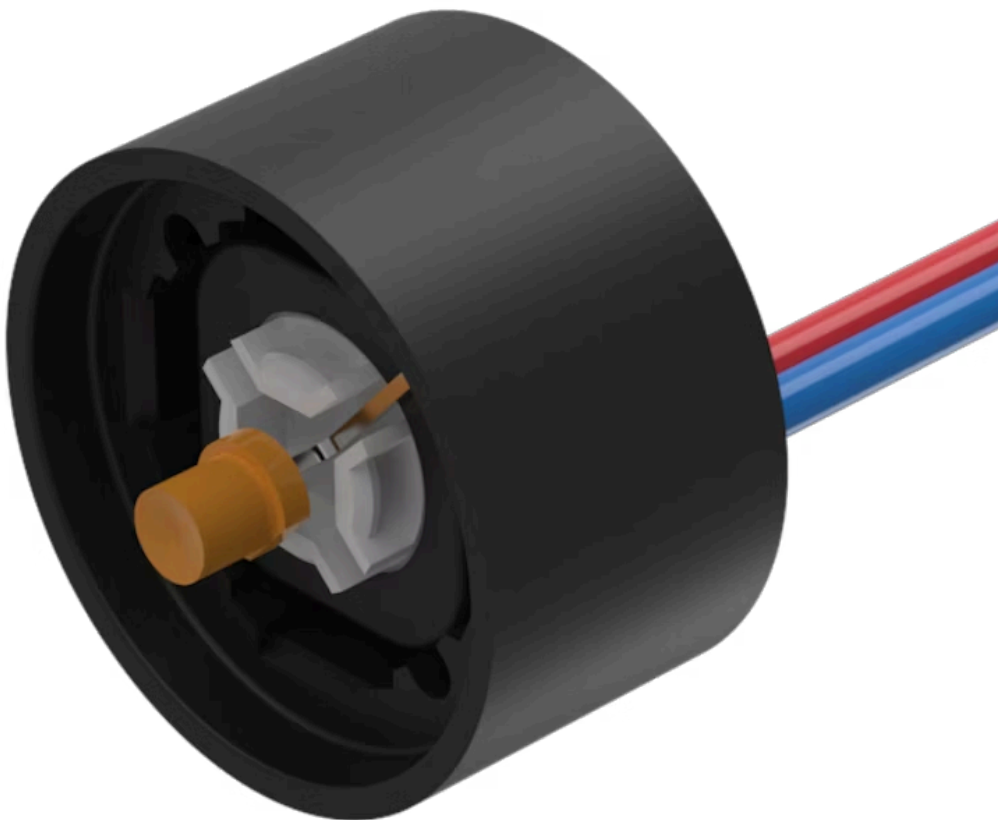

<https://eao.com/p/84-8001.3640>

Your product:



84-8001.3640

Indicator element

OPERATING-/INDICATION PART

Illumination colour: Amber

ELECTRICAL CHARACTERISTICS

Operating voltage: 24 V DC $\pm 10\%$

Lumi. Intensity: mcd

MECHANICAL CHARACTERISTIC

Terminal: Flat ribbon cable

Weight: 0.01 kg

AMBIENT CONDITION

IP Protection: IP40

CERTIFICATE

REACH: REACH compliant

RoHS: RoHS compliant

OTHER


Short Description: Indicator element, Amber, Single-LED, 24 V DC $\pm 10\%$, Flat ribbon cable

Kind of illumination: Single-LED

 
Hints: LED and built-in resistor included, Standard version: Cable length 300 mm, Other options on request: Customisation of cable and connectors, rear side fully sealed (IP 67), Protection degree (rear side): IP 40, upgrade to IP 67 with plug Part No. 84-900 possible. With applications where strong vibrations occur, the plugs may

become loose, Luminosity and wave length variations caused by LED manufacturing processes may cause slight differences regarding the illumination. The customer has to decide what resistor shall be used to the LED



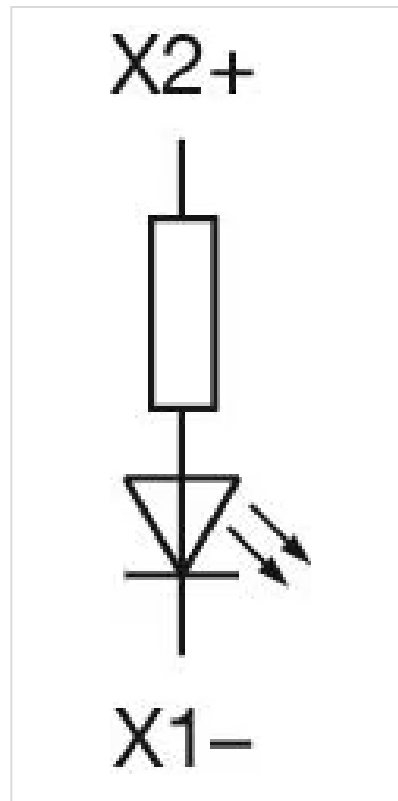







Wiring diagrams:



Component layouts:



Where to Buy

Distributor		Quantity in Stock		
	DigiKey	10 in stock	Buy	
	Mouser Electronics	1 in stock	Buy	
	RS Americas	0 in stock	Buy	
	Newark	0 in stock	Buy	
	Sager	0 in stock	Buy	

Powered by oemsecrets.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[84-8001.3640](#)