

Indicator element

84-8001.9620



<https://eao.com/p/84-8001.9620>

Your product:



84-8001.9620

Indicator element

OPERATING-/INDICATION PART

Illumination colour: White

ELECTRICAL CHARACTERISTICS

Operating voltage: 24 V DC $\pm 10\%$

Lumi. Intensity: mcd

MECHANICAL CHARACTERISTIC

Terminal: Plug-in terminal, 2.8 x 0.8 mm

Weight: 0.005 kg

AMBIENT CONDITION

IP Protection: IP40

CERTIFICATE

REACH: REACH compliant

RoHS: RoHS compliant

OTHER


Short Description: Indicator element, White, Single-LED, 24 V DC $\pm 10\%$, Plug-in terminal, 2.8 x 0.8 mm

Kind of illumination: Single-LED







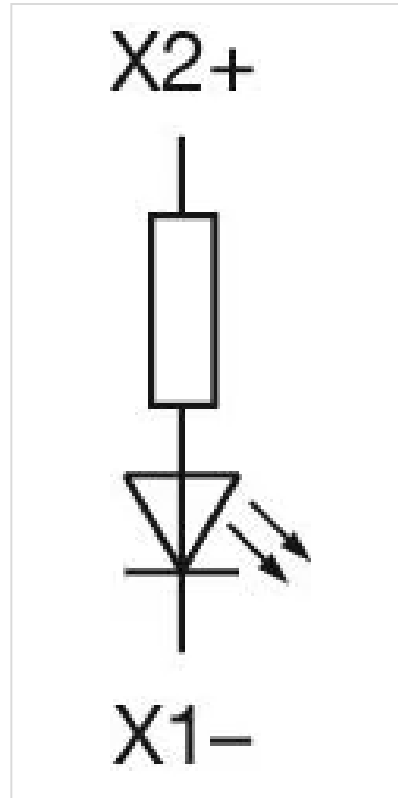



Hints: LED and built-in resistor included, Standard version: Cable length 300 mm, Other options on request: Customisation of cable and connectors, rear side fully sealed (IP 67), Protection degree (rear side): IP 40, upgrade to IP 67 with plug Part No. 84-

900 possible. With applications where strong vibrations occur, the plugs may become loose, Luminosity and wave length variations caused by LED manufacturing processes may cause slight differences regarding the illumination. The customer has to decide what resistor shall be used to the LED

Wiring diagrams:



Where to Buy

	Distributor	Quantity in Stock	
	DigiKey	4 in stock	Buy 
	Mouser Electronics	0 in stock	Buy 
	RS UK	0 in stock	Buy 
	RS Americas	0 in stock	Buy 
	Sager	0 in stock	Buy 

[Show more](#) 

Powered by oemsecrets.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[84-8001.9620](#)