


EAO – Your Expert Partner for Human Machine Interfaces

84-8511.2640 - Switching element with illumination

84-8511.2640 - Switching element with illumination

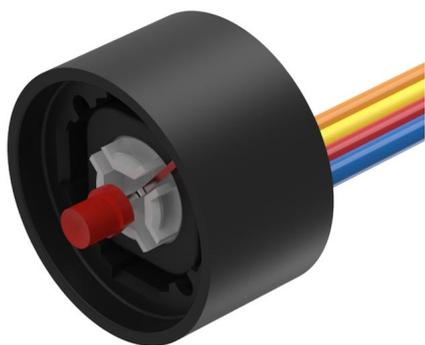

Attention: The preview is based on a sample product. This can differ from your current configuration.

Other Attributes

Weight	0,015 kg
Operating voltage	24 V DC \pm 10 %
Operation current	10 mA

IP-Rating

Protection degree	IP40
-------------------	------

Connection Method

Terminal	Flat ribbon cable
----------	-------------------

Switching element

Contact material	
Switching system	Short-travel element
Switching voltage	42 V AC/DC
Switching current	0.1 A
Contacts	1 NO


Illumination

LED colour	red
------------	-----

EAO – Your Expert Partner for Human Machine Interfaces

84-8511.2640 - Switching element with illumination

 Wiring diagram



Additional information

LED and built-in resistor included

Standard version: Cable length 300 mm with insulated ferrule, plug-in terminal 2.8 x 0.8 mm

Other options on request: Customisation of cable and connectors, rear side fully sealed (IP 67)

Protection degree (rear side): IP 40, upgrade to IP 67 with plug Part No. 84-900 possible. With applications where strong vibrations occur, the plugs may become loose

Luminosity and wave length variations caused by LED manufacturing processes may cause slight differences regarding the illumination

Legend

Contacts: NO = Normally open

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

EAO:

[84-8511.2640](tel:84-8511.2640)