

EAO – Your Expert Partner for Human Machine Interfaces

10-2H25.2049 - Single-LED

10-2H25.2049 - Single-LED



Attention: The preview is based on a sample product. This can differ from your current configuration.

Other Attributes

Weight	0,002 kg
Operation current	1,5 mA ± 15 %
Operating voltage	230 V AC $+10$ %

Illumination

Socket	BA9s
LED colour	white


Optics

Lumi. intensity	225 mcd
Dom. wavelength	x0.31/y0.32 nm

EAO – Your Expert Partner for Human Machine Interfaces

10-2H25.2049 - Single-LED

Dimensions

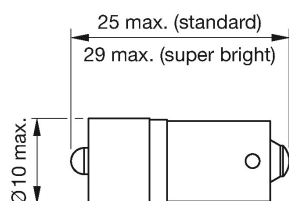

Additional information

The max. overall length of the lamp may not exceed 25mm

Electrical and optical data are measured at 25 °C

The specified 6 VDC, 24 VDC Bi-colour; 130 VAC, 130 DC und 230

VAC versions are built with a protection diode

Luminosity and wave length variations caused by LED

manufacturing processes may cause slight differences regarding
the illumination

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

EAO:

[10-2H25.2049](#)