

EAO – Your Expert Partner for Human Machine Interfaces

10-2524.3042 - Single-LED

10-2524.3042 - Single-LED



Attention: The preview is based on a sample product. This can differ from your current configuration.

Other Attributes

Weight	0,002 kg
Operation current	3 mA ±15 %
Operating voltage	130 V DC +10 %

Illumination

Socket	BA9s
LED colour	red


Optics

Lumi. intensity	120 mcd
Dom. wavelength	630 nm

EAO – Your Expert Partner for **Human Machine Interfaces**

10-2524.3042 - Single-LED

Dimensions

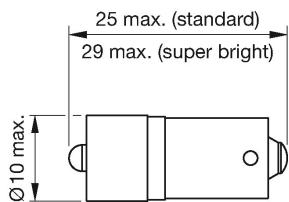

Additional information

The max. overall length of the lamp may not exceed 25mm

Electrical and optical data are measured at 25 °C

The specified 6 VDC, 24 VDC Bi-colour; 130 VAC, 130 DC und 230 VAC versions are built with a protection diode

Luminosity and wave length variations caused by LED manufacturing processes may cause slight differences regarding the illumination

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

EAO:

10-2524.3042