

EAO – Your Expert Partner for Human Machine Interfaces

10-2512.1149 - Single-LED

10-2512.1149 - Single-LED



Attention: The preview is based on a sample product. This can differ from your current configuration.

Other Attributes

Weight	0,002 kg
Operation current	7 mA \pm 15 %
Operating voltage	24 V AC/DC +10 %

Illumination

Socket	BA9s
LED colour	white


Optics

Lumi. intensity	1050 mcd
Dom. wavelength	x0.31/y0.32 nm

EAO – Your Expert Partner for Human Machine Interfaces

10-2512.1149 - Single-LED

Dimensions

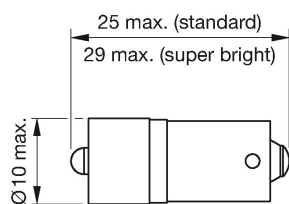

Additional information

The max. overall length of the lamp may not exceed 25mm

Electrical and optical data are measured at 25 °C

The specified 12, 24, 28, 48 VAC/DC versions are built with a bridge rectifier

Luminosity and wave length variations caused by LED manufacturing processes may cause slight differences regarding the illumination

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

EAO:

[10-2512.1149](#)