

# EAO – Your Expert Partner for Human Machine Interfaces

10-2106.3146 - Single-LED

## 10-2106.3146 - Single-LED



*Attention: The preview is based on a sample product. This can differ from your current configuration.*

### Other Attributes

Weight	0,001 kg
Operation current	15 mA $\pm$ 15 %
Operating voltage	6 V DC +10 %

### Illumination

Socket	T5.5
LED colour	blue


### Optics

Lumi. intensity	680 mcd
Dom. wavelength	470 nm

# EAO – Your Expert Partner for Human Machine Interfaces

10-2106.3146 - Single-LED

## Dimensions

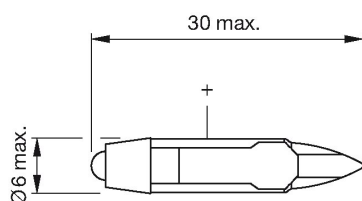

## Additional information

Luminous intensity data of the LEDs on direct voltage

Electrical and optical data are measured at 25 °C

The specified versions are built with a protection diode (halve wave rectifier) in series and the LED

Luminosity and wave length variations caused by LED manufacturing processes may cause slight differences regarding the illumination

For supply voltages above 48 V, it is necessary to use a voltage reduction element (external series resistor or transformer)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

EAO:

[10-2106.3146](#)