


EAO – Your Expert Partner for Human Machine Interfaces

61-4970.13 - Potentiometer

61-4970.13 - Potentiometer

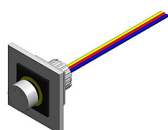

Attention: The preview is based on a sample product. This can differ from your current configuration.

Mounting

Mounting cut-out	21,2 mm x 21,2 mm
Design	flush

Front

Front bezel material	Plastic
Front bezel colour	black
Front shape	square
Front dimension	24 mm x 24 mm

Other Attributes

Weight	0,023 kg
Resistance	10 kOhm linear
Power	1 W
Slewing range	300 °

IP-Rating

Front protection	IP65
------------------	------

Connection Method

Terminal	Flat ribbon cable
----------	-------------------

Actuator

Housing material	Plastic
------------------	---------


Function

Potentiometer	
---------------	--


EAO – Your Expert Partner for Human Machine Interfaces

61-4970.13 - Potentiometer


Dimensions

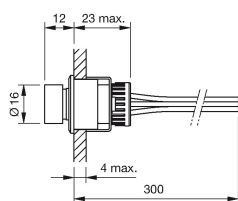

Mounting cut-outs

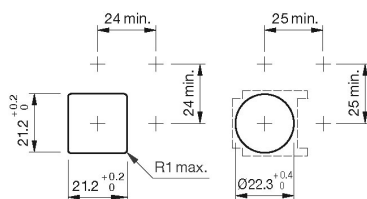

Wiring diagram

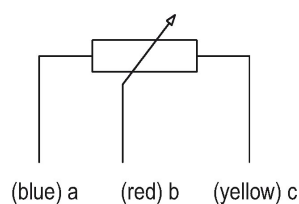

Component layout

Rearview
Potentiometer terminals



Conductor colour of flat ribbon cable
a = blue, b = red, c = yellow

Additional information

Cable length 300 mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

EAO:

61-4970.13