



EK SERIES

POWER ENTRY MODULE FILTERS



INTRODUCTIONS

1. EK Series filters are for UL 544 & UL 2601 health care equipment.
2. All part numbers are UL recognized, CSA certified and VDE approved.

COMPONENTS

PART NO.	L (mH)	C1 (uF)	C2 (uF)	R (MΩ)
03EK3M/AM	8	0.22	0.1	1
03EK3SM/AM				
03EK4M/AM				
06EK3M/AM	2.5			
06EK3SM/AM				
06EK4M/AM				
10EK3M/AM	1.6			
10EK3SM/AM				
10EK4M/AM				

Lg: 400uH (EK3AM, EK3SAM only)

MINIMUM INSERTION LOSS IN dB





COMMON MODE (L-G) IN 50 OHM SYSTEM									
CURRENT RATING	FREQUENCY-MHz								
	0.05	0.10	0.15	0.50	1.0	5.0	10	30	
3A (M)	22	27	32	42	36	20	15	6	
6A (M)	12	18	20	25	25	20	13	6	
*10A (M)	8	10	14	20	25	20	17	10	
3A (AM) (SAM)	22	27	32	30	36	22	18	6	
6A (AM) (SAM)	12	18	20	25	25	20	13	6	
*10A (AM) (SAM)	8	14	24	20	25	20	17	12	
DIFFERENTIAL MODE (L-L) IN 50 OHM SYSTEM									
3A (M)	2	4	18	48	55	50	50	35	
6A (M)	4	4	12	38	50	50	50	25	
*10A (M)	4	6	6	30	45	50	50	35	
3A (AM) (SAM)	35	35	45	50	55	40	25	10	
6A (AM) (SAM)	25	45	25	40	50	40	25	10	
*10A (AM) (SAM)	20	28	38	45	50	40	25	13	

*CSA approved 6A at 125/250VAC. VDE approved 6A at 250VAC.

SPECIFICATIONS

1. Maximum leakage current each
line-to-ground: @ 115VAC 60Hz: 2.0uA
@ 250VAC 50Hz: 5.0uA
2. Hipot rating (one minute)
line-to-ground: 2250VDC
line-to-line: 1450VDC
3. Operating frequency: 50/60Hz
4. Rated voltage: 115/250VAC

ELECTRICAL SCHEMATIC

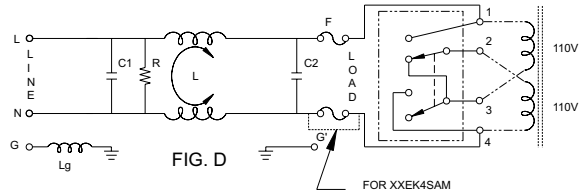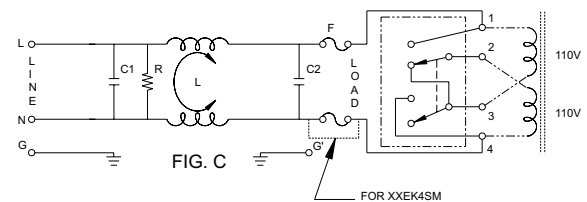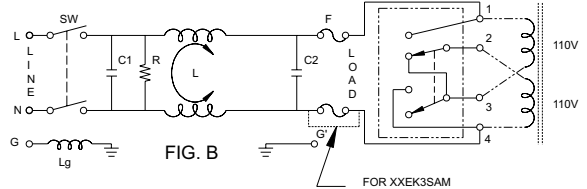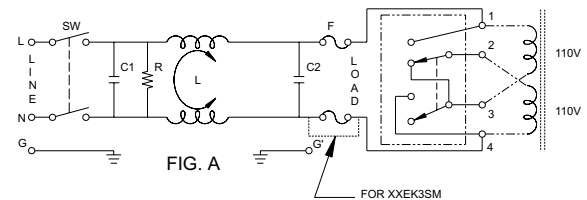

DELTA PART NO.	03EK3M 06EK3M 10EK3M	03EK3AM 06EK3AM 10EK3AM	03EK3SM 06EK3SM 10EK3SM	03EK3SAM 06EK3SAM 10EK3SAM	03EK4M 06EK4M 10EK4M	03EK4AM 06EK4AM 10EK4AM	03EK4SM 06EK4SM 10EK4SM	03EK4SAM 06EK4SAM 10EK4SAM
* FUSE	DOUBLE	DOUBLE	SINGLE	SINGLE	DOUBLE	DOUBLE	SINGLE	SINGLE
IEC CONNECTOR	Δ	Δ	Δ	Δ	Δ	Δ	Δ	Δ
**DOUBLE-POLE POWER SWITCH	Δ	Δ	Δ	Δ	—	—	—	—
VOLTAGE SELECTOR SW	Δ	Δ	Δ	Δ	Δ	Δ	Δ	Δ
ELECTRICAL SCHEMATIC	FIG. A	FIG. B	FIG. A	FIG. B	FIG. C	FIG. D	FIG. C	FIG. D




* UL, CSA & VDE approved
Current rating: UL-10A both at 125VAC & 250VAC.
CSA & VDE-6A at 250VAC.

** UL, CSA & VDE approved
Current rating: UL & CSA-10A both at 125VAC & 250VAC.
VDE-10A at 250VAC.
Electrical lifetime: 10,000 cycles.
Maximum inrush current: 51A.


MECHANICAL CONSTRUCTION






EK3M/AM/SM/SAM

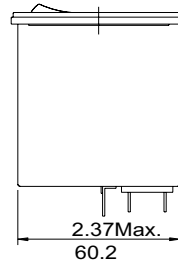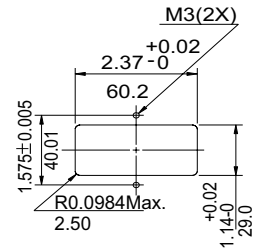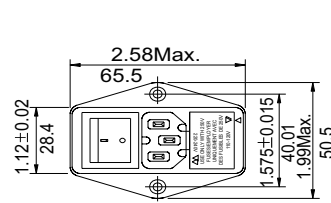


SUGGESTED MOUNTING CUTOUT

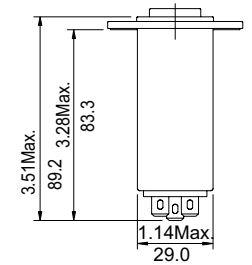

EK4M/AM/SM/SAM

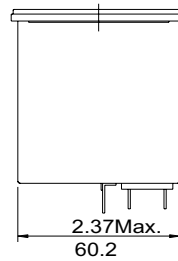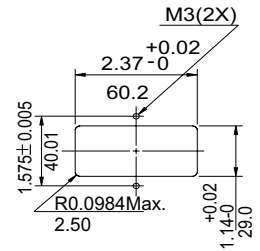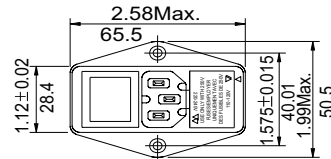

SUGGESTED MOUNTING CUTOUT

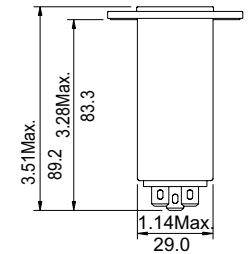

UNIT: $\frac{\text{INCH}}{\text{mm}}$

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Delta Electronics:](#)

[10EK3AM](#)