





- * Bearing Type
Ball Bearings
- * Material
Impeller: Plastic (UL 94V-0)
Frame: Die-cast Aluminum
- * Lead Wires :
UL 1007 AWG #24 OR Equivalent
Red Wire Positive (+)
Black Wire Negative (-)
- * Weight : 430g (15.17 oz)

AFB 172 x 150 x 25.4 MM SERIES


■ DIMENSIONS DRAWING

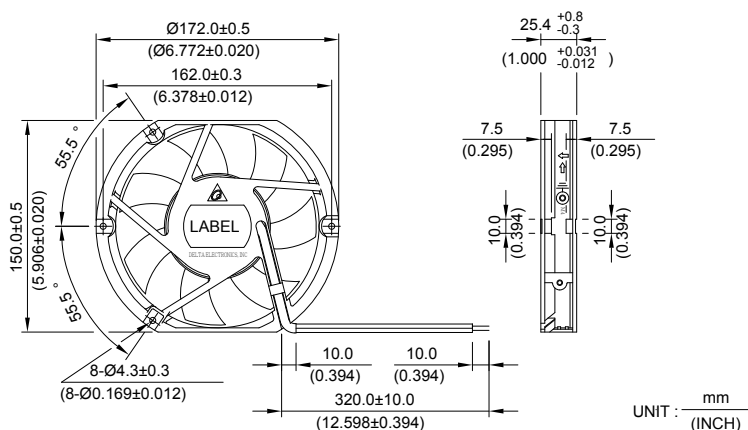

■ P & Q CURVE (AT RATED VOLTAGE)

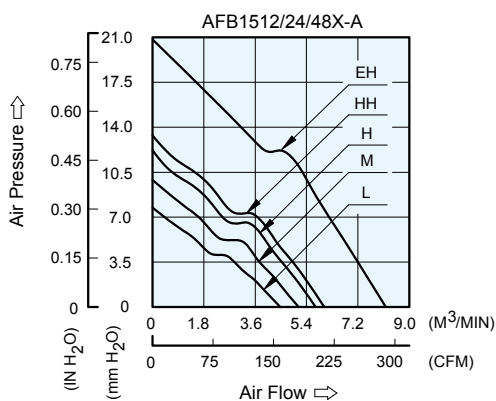

■ MOUNTING PANEL CUTOUT

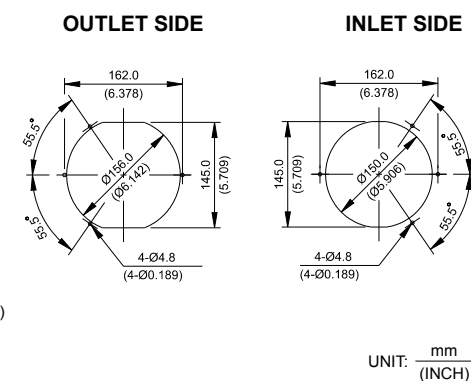

MODEL			Rated Voltage	Operating Voltage Range	Input Current	Input Power	Speed	Maximum Air Flow		Maximum Air Pressure		Noise
PART NO.	REV.	FUNCTION	VDC	VDC	Amp	Watt	R.P.M.	m³ /min	CFM	mmH₂O	IN H₂O	dB-A
AFB1512L	-A	-R00 / -F00	12	6.0 to 14.0	0.56	6.72	2400	4.553	160.77	7.75	0.305	46.0
AFB1524L	-A	-R00 / -F00	24	12.0 to 30.0	0.31	7.44						
AFB1548L	-A	-R00 / -F00	48	24.0 to 60.0	0.17	8.16						
AFB1512M	-A	-R00 / -F00	12	6.0 to 14.0	0.76	9.12	2700	5.134	181.32	9.70	0.382	49.0
AFB1524M	-A	-R00 / -F00	24	12.0 to 30.0	0.40	9.60						
AFB1548M	-A	-R00 / -F00	48	24.0 to 60.0	0.22	10.56						
AFB1512H	-A	-R00 / -F00	12	6.0 to 14.0	0.98	11.76	3000	5.735	202.54	11.85	0.467	52.0
AFB1524H	-A	-R00 / -F00	24	12.0 to 30.0	0.50	12.00						
AFB1548H	-A	-R00 / -F00	48	24.0 to 60.0	0.27	12.96						
AFB1512HH	-A	-R00 / -F00	12	6.0 to 14.0	1.17	14.04	3200	6.084	214.85	13.30	0.524	53.5
AFB1524HH	-A	-R00 / -F00	24	12.0 to 30.0	0.62	14.88						
AFB1548HH	-A	-R00 / -F00	48	24.0 to 60.0	0.31	14.88						
AFB1512EH	-A	-R00 / -F00	12	7.0 to 13.8	3.00	36.00	4300	8.230	290.64	20.85	0.821	61.5
AFB1524EH	-A	-R00 / -F00	24	15.8 to 27.6	1.60	38.40						

* Function type is optional.

* The max. air flow and the speed are measured in free air ; max. air pressure is measured at zero air flow.

* Noise is measured in anechoic chamber in free air, one meter from intake side.

* All readings are typical values at rated voltage.

* Specifications are subject to change without notice.


New




- * Bearing Type
 - * Ball Bearings
- * Material
 - Impeller : Plastic (UL 94V-0)
 - Frame : Die-Cast Aluminum
- * Lead Wires :
 - UL 1007 AWG #24 OR Equivalent
 - Red Wire Positive(+)
 - Black Wire Negative(-)
- * Weight : 435g (28.22 oz)

AFB 172 x 150 x 25.4 MM SERIES


■ DIMENSIONS DRAWING

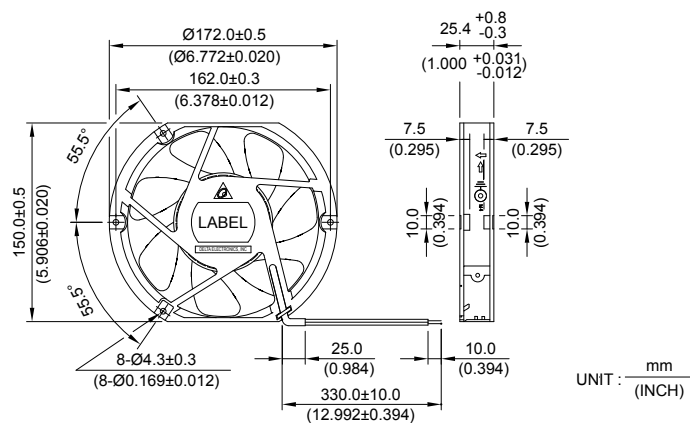

■ P & Q CURVE (AT RATED VOLTAGE)

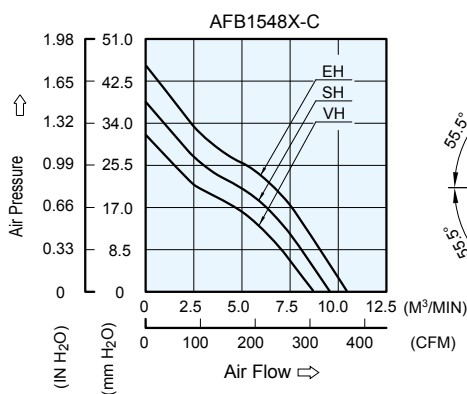

■ MOUNTING PANEL CUTOUT

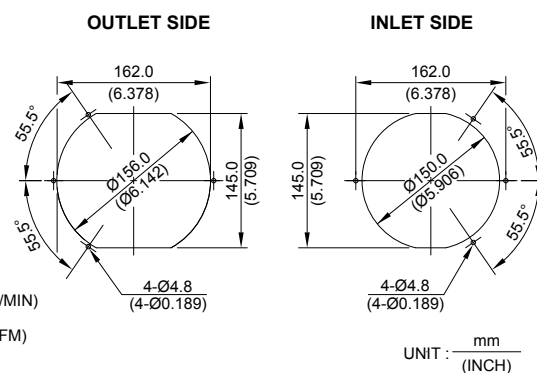

MODEL			Rated Voltage	Operating Voltage Range	Input Current	Input Power	Speed	Maximum Air Flow		Maximum Air Pressure		Noise
PART NO.	REV.	FUNCTION	VDC	VDC	Amp	Watt	R.P.M.	m ³ /min	CFM	mmH ₂ O	IN H ₂ O	dB-A
AFB1548VH	-C	-R00 / -F00	48	35.0 to 60.0	0.72	34.56	5000	8.700	307.24	31.82	1.253	64.5
AFB1548SH	-C	-R00 / -F00	48	35.0 to 60.0	0.92	44.16	5500	9.570	337.96	38.50	1.516	67.0
AFB1548EH	-C	-R00 / -F00	48	35.0 to 60.0	1.20	57.60	6000	10.440	368.68	45.82	1.804	69.0

* Function type is optional.

* The max. air flow and the speed are measured in free air ; max. air pressure is measured at zero air flow.

* Noise is measured in anechoic chamber in free air, one meter from intake side.

* All readings are typical values at rated voltage.

* Specifications are subject to change without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Delta Electronics:

[AFB1548L-AF00](#) [AFB1512HH-TA50](#) [AFB1524HH-AR00](#) [AFB1548H-AR00](#) [AFB1548L-A](#) [AFB1524M-A](#) [AFB1548H-A](#) [AFB1548M-AF00](#) [AFB1548HH-A](#) [AFB1548VH-C](#) [AFB1548HH-AF00](#) [AFB1548SH-C](#) [AFB1524H-A](#) [AFB1524EH-AF00](#) [AFB1548VH-CR00](#) [AFB1524M-AR00](#) [AFB1512L-AR00](#) [AFB1524EH-AR00](#) [AFB1548M-AR00](#) [AFB1524L-AF00](#) [AFB1548M-A](#) [AFB1512HH-AR00](#) [AFB1548SH-CR00](#) [AFB1512H-AF00](#) [AFB1512M-AF00](#) [AFB1512EH-AF00](#) [AFB1524HH-A](#) [AFB1512HH-A](#) [AFB1512H-AR00](#) [AFB1512L-AF00](#) [AFB1512M-AR00](#) [AFB1548L-AR00](#) [AFB1524HH-AF00](#) [AFB1524L-A](#) [AFB1512L-TA50](#) [AFB1512HH-AF00](#) [AFB1512M-A](#) [AFB1548H-AF00](#) [AFB1548VH-CF00](#) [AFB1512H-A](#) [AFB1524L-AR00](#) [AFB1512EH-A](#) [AFB1524H-AR00](#) [AFB1512EH-AR00](#) [AFB1548HH-AR00](#) [AFB1524M-AF00](#) [AFB1512L-A](#) [AFB1524EH-A](#) [AFB1548SH-CF00](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Delta Electronics:](#)

[AFB1512M-TA50](#)