


Internal Door mount



HEX120PA series

Dimension drawing

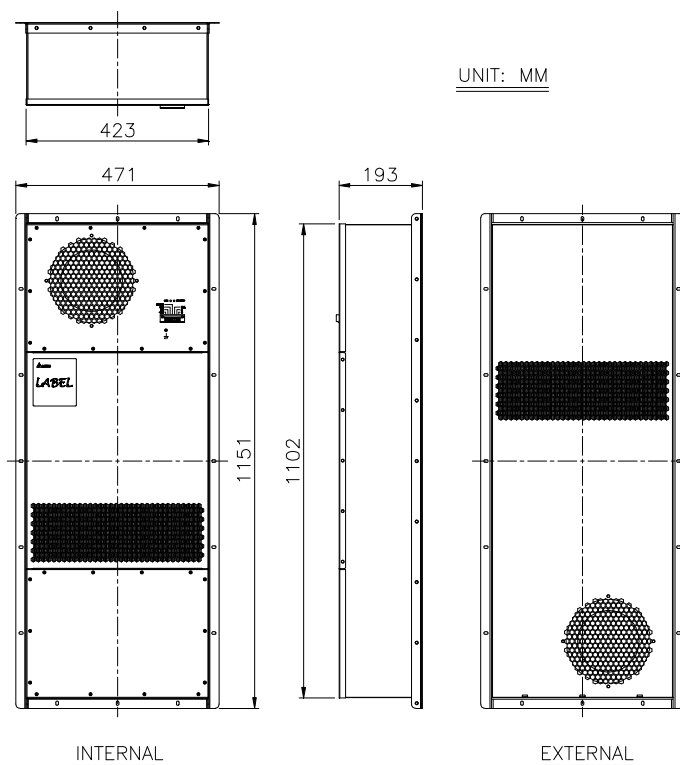

Features

- ◆ IP55 waterproof at external side
- ◆ Standalone temperature control
- ◆ RS-485 function
- ◆ Clear LED status indicator
- ◆ Dry contact alarm output

Design

- ◆ Air to air heat exchange
- ◆ Rated voltage at 48V
- ◆ High efficiency and reliable fan
- ◆ Easy installation and maintenance

Main feature	Unit	Specification
Dimension (H x W x D)	mm (in)	1151 x 471 x 193 (45 x 19 x 8)
Cooling capacity*Note	W/K (W/°F)	120 (67)
Rated voltage	VDC	48
Operating current	A	4.1
Operating power	W	197
Operating voltage range	VDC	40 ~ 60
Operating temperature range	°C	-10 ~ +65
Noise (1.5 meter)	dB-A	64.0
Weight	Kg (Lb)	33 (73)

* Note : The cooling capacity (W/K , W/°C or W/°F) is defined as $Q / (T_i - T_A)$

Q : Heat dissipation (W) from inside of cabinet

T_i : Return temperature of internal air circuit (K , °C or °F)

T_A : Ambient temperature of external air circuit (K , °C or °F)

* Specifications are subject to change without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Delta Electronics:](#)

[HEX120PA](#)