


HET200VB series

Dimension drawing

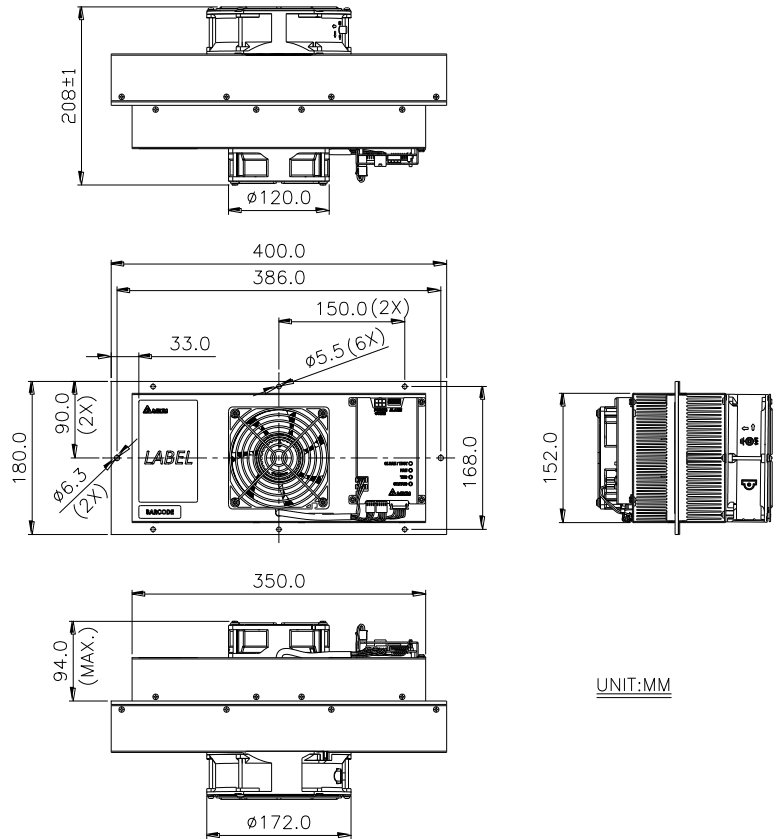

UNIT:MM

Features

- ◆ IP55 waterproof at external side
- ◆ FAN / TEC / Control fail alarm
- ◆ Clear LED status indicator
- ◆ Standalone temperature control
- ◆ High efficiency and reliable fan modules

Design

- ◆ High efficiency of cooling & Heating
- ◆ Thermal electric cooling module
- ◆ Rated voltage at 24V
- ◆ Built-in controller

Main feature	Unit	Specification
Dimension (H xW xD)	mm	180x 400 x 208
Cooling capacity($\Delta T=0^{\circ}\text{C}$)	W	200
Rated voltage	VDC	24 (TYP.)
Operating voltage range	VDC	21~28
Operating current	A	12.2
Power consumption	W	292.8
Operating temperature range	$^{\circ}\text{C}$	-40 ~ +55
Weight	Kg	9.0
Acoustic noise (1 meter)	dB-A	61

* Specifications are subject to change without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Delta Electronics:](#)

[HET200VB](#)