


HET200VC series

Dimension drawing

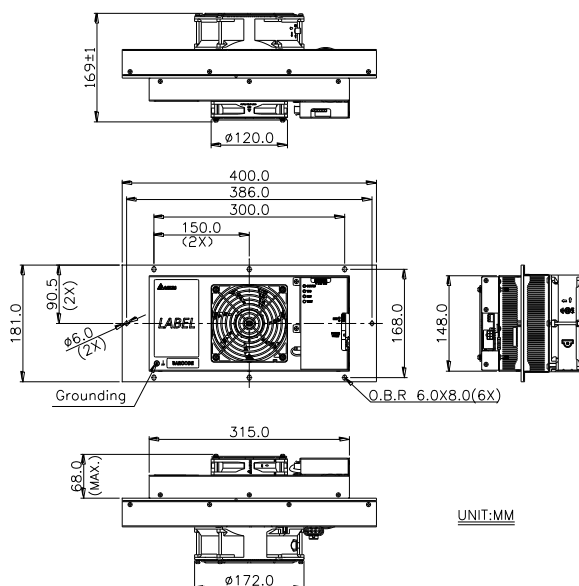

Features

- ◆ IP55 waterproof at external side
- ◆ FAN / TEC / Control fail alarm
- ◆ Clear LED status indicator
- ◆ Standalone temperature control
- ◆ High efficiency and reliable fan modules

Design

- ◆ High efficiency of cooling & Heating
- ◆ Thermal electric cooling module
- ◆ Rated voltage at 24V
- ◆ Built-in controller

Main feature	Unit	Model Number
		HET200VC
Outline dimension	mm	400 H x 181 W x 169 D
Weight	Kg	6.0 ± 0.5
Cooling capacity ($\Delta T = 0^{\circ}C$)	W	200
Heating capacity @-40° C	W	225
Rated voltage	VDC	24 (TYP.)
Operating voltage range	VDC	20-28
Actuality Current	A	12A(TYP.)
Power Consumption	W	288
Operating temperature	°C	-40~55
Internal airflow rate	CFM	85 (TYP.)
External airflow rate		115 (TYP.)
Acoustic noise at 1M :	dB-A	61.0 dB-A(Typ.)
(Sound pressure)		65.0(Max.)

* Specifications are subject to change without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Delta Electronics:](#)

[HET200VC](#)