

Embedded Computing Peripherals




P/N 1700090301

ASS'Y COM port 30 cm D-SUB 9P to 4P 2.0 mm



P/N 1703040157

RS-422/485 wire w/D-SUB COM 4P 15 cm

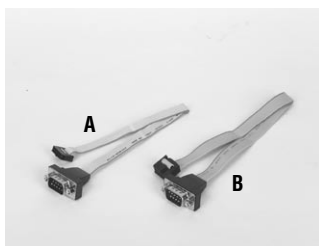

A. P/N 1700100250

Cable ASS'Y COM port 25 cm D-SUB 9P to 10P 2.0 mm


B. P/N 1701100300

Cable Flat cable 10P 30 cm gray D-SUB (9P-10P)



P/N 1701090401

Flat cable D-SUB 9P (M)/IDC 10P 40cm w/bracket

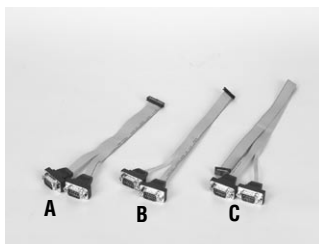

A. P/N 1701200180

Cable Flat cable 18 cm IDC 20P 2.0 mm/ 2 COM PCM-9576 use

B. P/N 1701140201

Cable Flat 14-pin 2.0 mm 20 cm secondary port 9-pin (M)


C. P/N 1700000445

Cable Flat cable D-SUB 9P*2/IDC 14P-2.0mm 45cm



P/N 1701200220

Cable for PCA-6753FC 20P 22 cm COM3, 4

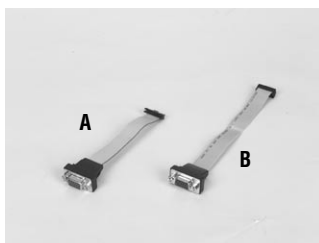

A. P/N 1701160101

Cable ASS'Y VGA 10 cm D-SUB 15P to 16P 2.0 mm


B. P/N 1701160150

Cable ASS'Y VGA 15 cm D-SUB 15P to 16P 2.0 mm PCM-9550 use



P/N 1701260301

Flat cable 26P 30 cm gray 26-25 D-SUB w/o bracket

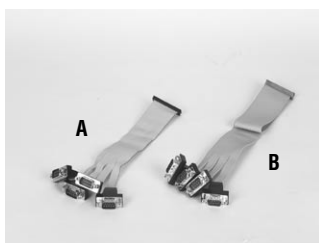

A. P/N 1701400181

Flat cable 18 cm IDC 40P 2.0 mm/4 COM PCM-9570 use

B. P/N 1700000447


Flat cable D-SUB 9P (M)/IDC 40P-2.0 mm 45 cm



P/N 1701100202


Flat cable 20 cm IDC 10P 2.0 mm/RJ45 PCM-9570 use

Embedded Computing Peripherals

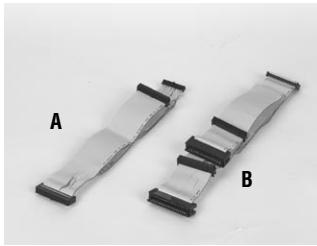


A. P/N 1701340603
Flat cable 34P 60 cm
FC34/34/HOUSING34 Idiot-proof

B. P/N 1701340700
Flat cable 34P 70 cm gray
5.25" & 3.5" FDD

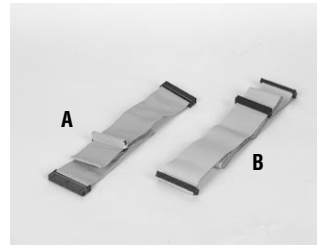

A. P/N 1701400452
Flat cable 40P 45 cm gray for DMA-66
PIN20 I.P.

B. P/N 1701400601
Flat cable 40P 60 cm gray for 2 AT bus
HDD

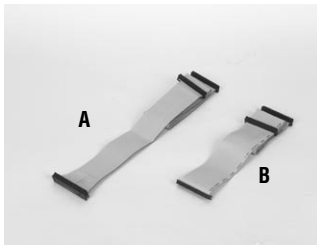


A. P/N 1701440504
Flat cable 44P 50 cm IDC 44P/44P/40P
keyed


B. P/N 1701440350
Flat cable 44P 35 cm gray IDC44P/
IDC44P/IDC44P



P/N 1701440500
Flat cable 40P 50 cm gray IDC40P/
IDC40P/HOUSING44P

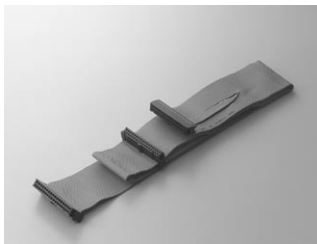

P/N 1700340640
Flat Cable 34P 64 cm 3.5" FDD x 2 for
CPU card

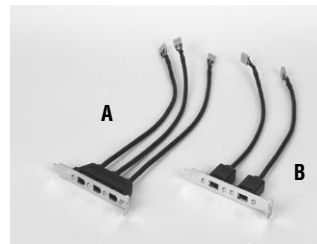

A. P/N 1700000720
Cable IEEE1394 3 ports/10P-2.54 mm
* 3 30.5 cm


B. P/N 1700000644
Cable IEEE1394*2/10P-2.54 mm
* 2 25 cm



P/N 9689000068
Purch jumper package Y * 15 + R *
5+1BAG




P/N 9689000002
Mini jumper * 10 pcs package (black)

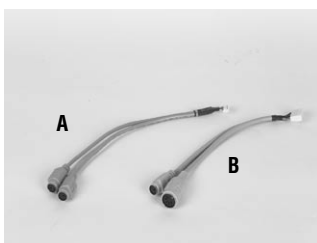

A. P/N 1703060191
Cable 6P-2.0 mm housing/6P (PS/2)/6P
(K/B) 19 cm

B. 1700060200

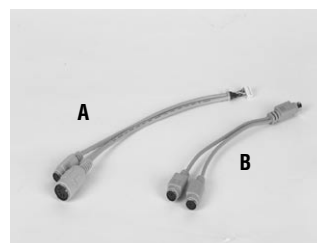


A. P/N 1700060204

B. P/N 1700060202
Cable 6P-6P-6P 20 cm PS/2
KB & mouse



P/N 1700060202
Cable 6P-6P-6P 20 cm PS/2
KB & mouse

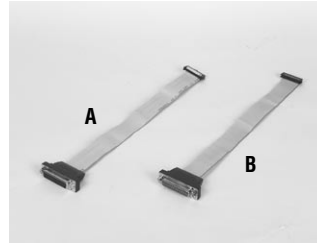

A. P/N 1700260250
Cable ASS'Y LPT port 25 cm 25P to
26P 2.0 mm

B. P/N 1700000446
COM, printer cable 2.5 mm IDC 26P
2.54 mm 45 cm



P/N 9681000044
Purch 26-34 pin FDD cable converter
(+5 V)




A. P/N 1701080300
Flat cable 8P 30 cm FD-0800-30

B. P/N 1701140300
Flat cable 14P-2.0 mm 30 cm




P/N 1703030300
Wire 3P-3P 30 cm WHT/BLK/BLU for
PCM-9570

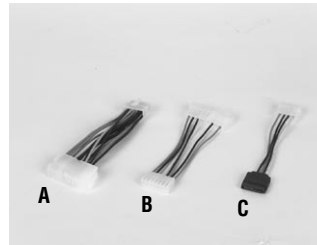

A. P/N 1700000265
Wire ATX-20P (M)/12P (F) 10 cm
PCM-9581

B. P/N 1703080101
Wire 7P/Big 4P*2 10 cm

C. P/N 1703150102
Wire Big 4P/Series ATA power 15P
10 cm

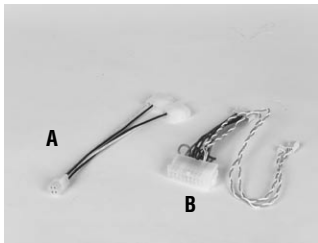


A. P/N 170304015K
Wire Big 4P*2/4200-H-4P 15 cm

B. P/N 1703200380
Wire ATX 20P/8P+3P+3P 38 cm for
PCM-3370



A. P/N 1700000719
Cable USB 4 ports/10P-2.54 mm
* 2 30.5 cm

B. P/N 1700000601
Cable USB 4 ports/10P 2.0 mm 30.5 cm

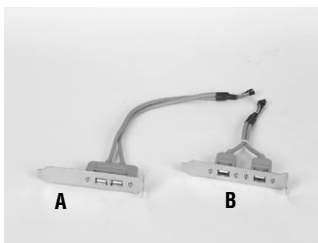

A. P/N 1703100260
Wire 10P 26 cm IDE 2.0 mm For USB
2 port 1.9"

B. P/N 1703100121
Wire 10P 12 cm IDC 2.0 mm for USB
2 port MBPC use




P/N 1700100170
USB Cable adaptor 17.5 cm 2CH
w/guard hole No. 10P

Embedded Computing Peripherals

**P/N 1703400156**


Wire DF13-40P/4 COM 15 cm for
PCM-9580

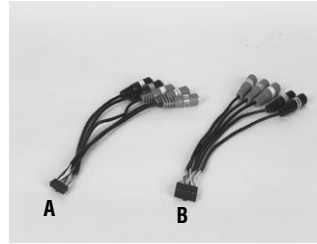**A. P/N 1700160160**

Audio cable for PCM-5820/L 16-pin
16 cm (2.0 mm)

B. P/N 1700160000

Cable for PCM-5862 16-pin audio
connector

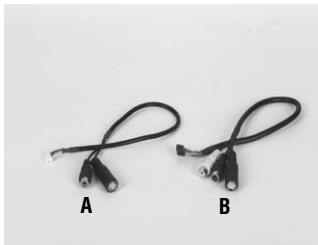**A. P/N 1703050306**

Wire 30 cm 5P TV-out (S-Video, Comp.
-Video)

B. P/N 1703140300

RCA jack S-video 30 cm 14P 2 mm
video in/out

**A. P/N 1703100152**

Audio cable 10P 2.0 mm 15 cm for
PCM-9372

A. P/N 1703060053

Cable 6P (MINI-DIN)-6P (Wafer 2.0 mm)
5 cm

**P/N 1750129010**

Battery 3V/210 mAh CR2032WK with
wire ASS'Y

**P/N 1700071000**

Cable serial ATA 7P/7P 100 cm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[1703100260](#) [1701200220](#) [1700000265](#) [1703050306](#) [1750129010](#)