

C-DSD7055N50FH-01

55" FHD Video Wall Display



Features

- 55" Full HD Full HD LED for brilliant images
- IPS display technology
- Advanced color calibration
- Designed for 24/7 operation
- Narrow bezel design
- Bezel thickness 3.5mm
- Bezel width: Top/Left:2.3mm; Bottom/Right: 1.2mm
- Open pluggable specification design
- Smart power for energy saving- lower total cost of ownership
- Keep content up and running with Failover

Introduction

The Advantech C-DSD7055N50FH-01 ultra-narrow bezel display create the most stunning video walls and full HD image quality. Impress your audience with the most impactful video wall.

Specifications

LCD Panel	Display Size	55" LED backlight Panel (Full HD)
	Resolution	1920 x 1080
	View Angle	89°/89°(H), 89°/89°(V)
	Brightness	500 (cd/m ²)
	Backlight Life (Hrs)	50,000 (Hrs)
	Contrast Ratio	1400:1
	Response Time	12 ms
	Color Support	1073M colors
Environment	Operation Temperature	0-40C
	Storage Temperature	-20-60C
	Relative Humidity	20 ~ 80%
Mechanical	Dimensions (W x H x D)	1213.4 x 686.9 x 103.35mm
	Gross Weight	29.2kg
	VESA Mounting	400x400 (mm)
System	Power	Consumption 175W (On mode); Standby power consumption:<0.5W;
	Regulatory	CE, FCC, ClassB, UL/cUL, GOST, CB, EPEAT
	Video input	DisplayPort, HDMI, DVI-D, VGA, Component(RCA), Composite(RCA)
	Video output	DVI-I, VGA, DisplayPort
	Audio input	3.5mm jack, Audio Left/Right(RCA)
	Audio output	External speaker connector, Audio Left/Right(RCA)

All product specifications are subject to change without notice


Last updated: 7-January-2016

Advantech Corp

13 Whatney, Irvine, CA. 92618 Toll free: 800-866-6008 Tel: 949-420-2500 www.Advantech.com Email: ecginfo@advantech.com

Dimensions

Unit: mm

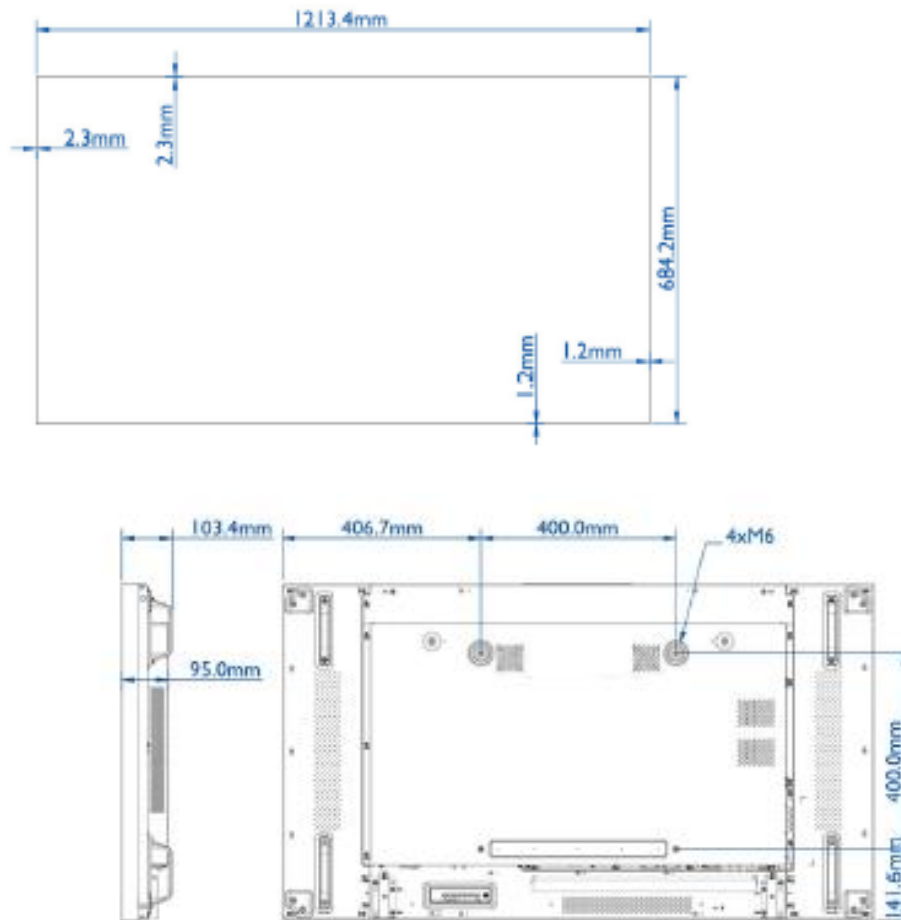

Ordering Information

Model Name
C-DSD7055N50FH-01

Package Dimension/Weight

Description	Dimension
Box Dimension	61.15" x 37.8" x 17.7" (W x H x D)
Carton Weight	97.7 lbs
Pallet Quantity	6 pcs

Packing List

P/n:	Description	Qty:
N/A	Remote control	1
N/A	VGA cable	1
N/A	RS232 cable	1
N/A	Edge alignment pins	1 set
N/A	Edge alignment plates	1 set
XNNC5001-EFK5583	Left and right Edge kit	1 set
XNNC5001-EFK5581	Top and Bottom Edge kit	1 set

Note: Package contents are subject to change without prior notice

Advantech Corp
13 Whatney, Irvine, CA. 92618 Toll free: 800-866-6008 Tel: 949-420-2500 www.Advantech.com Email:
ecginfo@advantech.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[C-DSD7055N50FH-01](#)