




## FireWire 3-Port PCI

3-port 1394 (FireWire) PCI adapter

Part #: **NN-400012-S8**

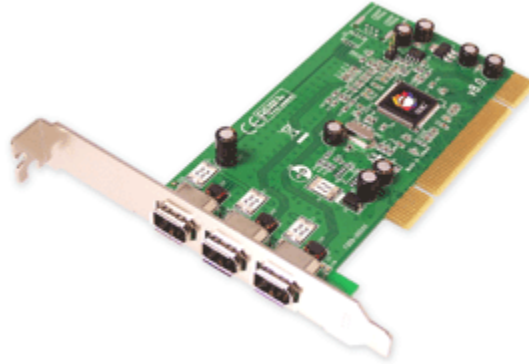

### Key Features and Benefits

- Three external IEEE 1394 (FireWire) ports support DV camcorders, hard disk, removable drives, scanners, printers and other 1394 audio/video devices including TV, VCR, DVD with data transfer rates up to 400Mb/s
- Supports both PC and Mac
- Works with Sony, Panasonic, Cannon, Sharp, JVC and many other DV camcorders for digital video creating/editing

### Specifications

- Regulatory approval(s): FCC Class B (DoC) & CE
- RoHS-compliant
- Chip: TSB43AB23 (TI single chip)
- Bus type: 32-bit PCI
- Port type: 3 IEEE external 1394 ports
- Compliant with IEEE 1394-1995, 1394a-2000 and OHCI 1.1 standards
- Compliant with PCI Plug-n-Play 2.2
- Hot-swapping feature allows you to connect/disconnect devices without powering down the system
- Supports serial bus data transfer rates of 100, 200 and 400Mb/sec
- Adds 3 IEEE 1394 ports to your PC for high-speed I/O connection and supports up to 63 devices

### System Requirements

- PC:
  - Pentium® or equivalent computer with one available PCI slot
  - Windows® 7 (32-/64-bit) / Vista (32-/64-bit) / XP (32-/64-bit) / Server 2003 & 2008 (32-/64-bit) / 2000 / ME / 98SE
- MAC®:
  - Power Mac® computer with an available PCI slot
  - Mac OS® 8.6 or later

### Package Contents

- FireWire 3-port PCI
- User's manual



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[96FW-400-3P-P-SI1](#)