



1080p
Full HD

96KVM-H17V8U-XX

Drawer Features & Display Benefits

- ▶ 1U 17" FHD LCD console drawer w/ combo DB-15 8-port KVM
- ▶ Support Full HD with 1080p resolution
- ▶ Green LED-backlit panel technology
- ▶ 104-key keyboard with touchpad
- ▶ New enhanced aesthetics with molded front handle
- ▶ Short depth design of 580mm



Specifications

• LCD Panel

Size (diagonal) :	17.3" widescreen TFT
Max resolution :	1920 x 1080
Brightness (cd/m2) :	400
Backlight :	LED
Colors :	16.7 M, 8-bit
Contrast ratio (typ) :	600 : 1
Viewing angle (H/V) :	160° x 140°
Active area (mm) :	382 x 215
MTBF (hrs) :	50,000
Video input :	VGA

• Keyboard layout : USA English

• Weight

Net :	11.6 kgs / 25.5 lbs
Gross :	17.5 kgs / 38.5 lbs

• Casing Color : Black (RAL 9005)

• Dimensions

Product :	441.6 x 580 x 44 mm / 17.4 x 22.8 x 1.73 inch
Packing :	590 x 808 x 140 mm / 23.2 x 31.8 x 5.5 inch

• Power Input : Auto-sensing 100 to 240VAC, 50 / 60Hz

• Power Consumption withg KVM integration

Screen on :	Max. 55W
Power saving mode :	Max. 34W

 
• Environmental

Operating temperature :	0 to 55°C degree
Storage temperature :	-20 to 60°C degree
Operating humidity :	20~90%, non-condensing
Storage humidity :	5 ~90%, non-condensing
Operating altitude :	16,000 ft
Non-operating altitude :	40,000 ft
Shock :	10G acceleration (11ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• Regulatory

Safety :	FCC & CE certified
Environmental :	RoHS2 & REACH compliant

Combo DB-15 KVM



KVM port : 8 x combo DB-15 connector

Server Support

Video : Resolution up to 1920 x 1080 / 1920 x 1200


KVM Switching : via Front button, OSD menu & hotkeys

Connectivity : Combo 4-in-1 KVM cable

Combo KVM Cable : CE-6, 6 feet combo KVM cable (bundle 8 pcs)
CE-10, 10 feet combo KVM cable (optional)
CE-15, 15 feet combo KVM cable (optional)
(Server end : VGA + USB or PS/2)
(KVM port : VGA)

Standard Keyboard

Ge G keyboard integrated with touchpad

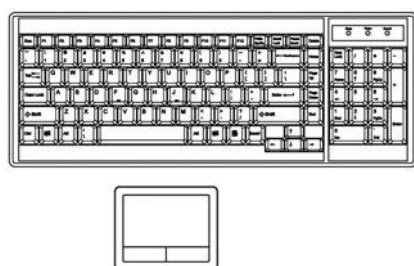

Optional layouts

EMEA	United Kingdom	Germany	France	Spain	Norway
	Italy	Russia	Switzerland	Netherlands	Portugal
Asia					
	China	Japan	Korea	Arabia	Turkey

Ordering Part Number

Model	Plug Type
96KVM-H17V8U-EU	European Plug
96KVM-H17V8U-IN	Indian Plug
96KVM-H17V8U-US	US Plug
96KVM-H17V8U-UK	UK Plug

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[96KVM-H17V8U-US](#) [96KVM-H17V8U-UK](#)