

## 96KVM-R17V1C-XX



### Drawer Features & Display Benefits

- ▶ 1U 17" LCD console drawer
- ▶ Green LED-backlit panel technology
- ▶ 104-key keyboard with touchpad
- ▶ New enhanced aesthetics with molded front handle
- ▶ Short depth design of 460mm



REACH

### Specifications

#### • LCD Panel

|                        |             |
|------------------------|-------------|
| Manufacturer :         | <b>AUO</b>  |
| Size (diagonal) :      | 17" TFT     |
| Max resolution :       | 1280 x 1024 |
| Brightness (cd/m2) :   | 250         |
| Backlight :            | LED         |
| Colors :               | 16.7 M      |
| Contrast ratio (typ) : | 1000 : 1    |
| Viewing angle (H/V) :  | 170° x 160° |
| Active area (mm) :     | 338 x 270   |
| MTBF (hrs) :           | 30,000      |
| Video input :          | VGA         |

#### • Keyboard layout

USA English

#### • Casing Color :

Black (RAL 9005)

#### • Power Input :

Auto-sensing 100 to 240VAC, 50 / 60Hz

#### • Power Consumption (single console)

|                     |          |
|---------------------|----------|
| Screen on :         | Max. 25W |
| Power saving mode : | Max. 4W  |
| Power button on :   | Max. 1W  |

#### • Environmental

|                          |                                  |
|--------------------------|----------------------------------|
| Operating temperature :  | 0 to 55°C degree                 |
| Storage temperature :    | -20 to 60°C degree               |
| Operating humidity :     | 20~90%, non-condensing           |
| Storage humidity :       | 5 ~90%, non-condensing           |
| Operating altitude :     | 16,000 ft                        |
| Non-operating altitude : | 40,000 ft                        |
| Shock :                  | 10G acceleration (11ms duration) |
| Vibration :              | 5~500Hz 1G RMS random vibration  |

#### • Regulatory

|                 |                         |
|-----------------|-------------------------|
| Safety :        | cUL, FCC & CE certified |
| Environmental : | RoHS2 & REACH compliant |

#### • Weight (single console)

|         |                     |
|---------|---------------------|
| Net :   | 12 kgs / 26 lbs     |
| Gross : | 16.6 kgs / 36.5 lbs |

#### • Dimensions (single console)

|           |                                               |
|-----------|-----------------------------------------------|
| Product : | 441.6 x 460 x 44 mm / 17.4 x 18.1 x 1.73 inch |
| Packing : | 590 x 808 x 140 mm / 23.2 x 31.8 x 5.5 inch   |

### Console Cable

#### CE-6

 

6 feet Combo KVM cable

- VGA + USB or PS/2, server end
- DB15 (VGA, USB KB & MS), console port

### Standard Keyboard



G keyboard integrated with touchpad

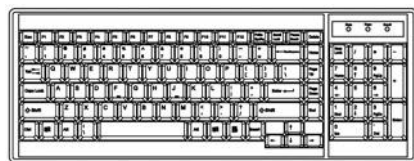

#### Optional layouts

|      |                |         |             |             |          |
|------|----------------|---------|-------------|-------------|----------|
| EMEA |                |         |             |             |          |
|      | United Kingdom | Germany | France      | Spain       | Norway   |
| Asia |                |         |             |             |          |
|      | Italy          | Russia  | Switzerland | Netherlands | Portugal |
|      |                |         |             |             |          |
|      | China          | Japan   | Korea       | Arabia      | Turkey   |

### Ordering Part Number

| Model           | Plug Type     |
|-----------------|---------------|
| 96KVM-R17V1C-EU | European Plug |
| 96KVM-R17V1C-IN | Indian Plug   |
| 96KVM-R17V1C-US | US Plug       |
| 96KVM-R17V1C-UK | UK Plug       |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[96KVM-R17V1C-US](#)