



96KVM-R19V1C-XX

Drawer Features & Display Benefits

- ▶ 1U 19" LCD console drawer
- ▶ Green LED-backlit panel technology
- ▶ 104-key keyboard with touchpad
- ▶ New enhanced aesthetics with molded front handle
- ▶ Short depth design of 500mm



REACH

Specifications

• LCD Panel

Manufacturer :	AUO
Size (diagonal) :	19" TFT
Max resolution :	1280 x 1024
Brightness (cd/m2) :	250
Backlight :	LED
Colors :	16.7 M
Contrast ratio (typ) :	1000 : 1
Viewing angle (H/V) :	170° x 160°
Active area (mm) :	376 x 301
MTBF (hrs) :	30,000
Video input :	VGA

• Keyboard layout :

USA English

• Casing Color :

Black (RAL 9005)

• Power Input :

Auto-sensing 100 to 240VAC, 50 / 60Hz

• Power Consumption (single console)

Screen on :	Max. 25W
Power saving mode :	Max. 4W
Power button on :	Max. 1W

• Environmental

Operating temperature :	0 to 55°C degree
Storage temperature :	-20 to 60°C degree
Operating humidity :	20~90%, non-condensing
Storage humidity :	5 ~90%, non-condensing
Operating altitude :	16,000 ft
Non-operating altitude :	40,000 ft
Shock :	10G acceleration (11ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• Regulatory

Safety :	cUL, FCC & CE certified
Environmental :	RoHS2 & REACH compliant

• Weight (single console)

Net :	12.7 kgs / 27.9 lbs
Gross :	17.3 kgs / 38.1 lbs

• Dimensions (single console)

Product :	441.6 x 500 x 44 mm / 17.4 x 19.7 x 1.73 inch
Packing :	590 x 808 x 140 mm / 23.2 x 31.8 x 5.5 inch

Console Cable


CE-6

6 feet Combo KVM cable

- VGA + USB or PS/2, server end
- DB15 (VGA, USB KB & MS), console port

Standard Keyboard

Ge G keyboard integrated with touchpad

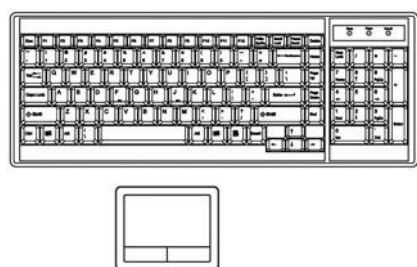

Optional layouts

EMEA	United Kingdom	Germany	France	Spain	Norway
	Italy	Russia	Switzerland	Netherlands	Portugal
Asia					
	China	Japan	Korea	Arabia	Turkey

Ordering Part Number

Model	Plug Type
96KVM-R19V1C-EU	European Plug
96KVM-R19V1C-IN	Indian Plug
96KVM-R19V1C-US	US Plug
96KVM-R19V1C-UK	UK Plug

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[96KVM-R19V1C-US](#)