


96ND1T-ST-SG7E

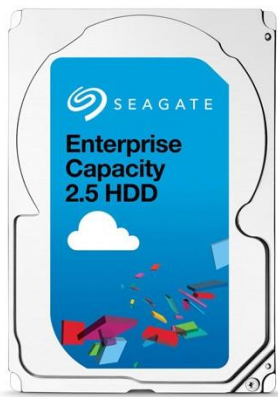

Features

- 7200 RPM spindle speed
- 128 MB data buffer
- PowerChoice™ for selectable power savings
- Top Cover Attached motor for excellent vibration tolerance
- High instantaneous (burst) data transfer rates (up to 600MB per second)

Spec

Product	96ND1T-ST-SG7E
Product Description	Seagate 2.5" 1TB SATA 7KRPM 128MB v3 Enterprise
Application	Server Storage
Manufacturer Part Number	ST1000NX0313
Manufacturer	Seagate
Capacity	1TB
Model Generation	Enterprise Capacity 2.5 HDD v3 SATA
Size	2.5 IN
Interface	SATA
24X7 Operation	Yes
Max Transfer Rate	600MB/s
Spindle Speed	7200RPM
Cache Size	128MB
Average Read Seek Time	4.16MS
Thickness	N/A
Operating Temperature	NonIND Temp
MTBF	1,400,000 HOURS
RoHS Status	YES

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[96ND1T-ST-SG7E](#)