

# 96PSA-A84W12P4

Adapter Power Supply



## Features

- Full range AC input 100-240V
- Meet Energy Star EPS 2.0 /ErP Lot 7
- No load Power Consumption  $\leq 0.21W$
- High Reliability
- Available for high altitude(5,000M) and DOE level VI

## General

Advantech Part Number	96PSA-A84W12P4
Description	FSP ADP A/D 100-240V 84W 12V C14 TERMINAL BLOCK 2 PIN
Manufacturer	FSP Technology

## Output Specifications

Output Power	84W
Output Voltage & Current	12V@7A
Efficiency (%)	88% minimum
Main Connector	Signal

## Mechanical

Dimension (L x W x H)	160x58x32.3mm
MTBF	100K hours at 25°C

## Input Specifications

Input Voltage Range	100 - 240V
Input Frequency	47-63Hz
PFC Function	W/ PFC
Input Current Type	AC to DC


## Environmental Specification

Storage Temp.	-30 to +60°C
Storage Humidity	8 – 80% RH
Operating Temp. (°C)	0 to + 40°C

## Safety

Safety & EMC	Class B
Safety Standard	CUL / CB / CCC / CE / FCC / GS / KC / RCM / BSMI / PSE / IRAM / UkrCEPRO / NOM / CU / Efficiency Level VI
RoHs	YES

## Drawing

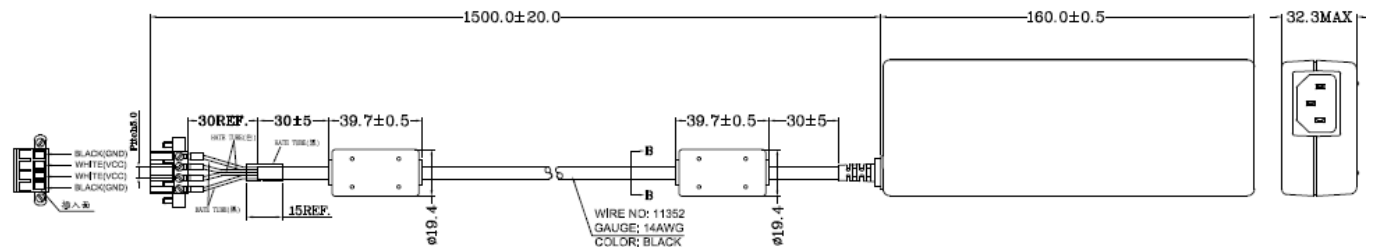

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[96PSA-A84W12P4](#)