



RKP117 / 119 Single Console



Drawer Features & Display Benefits

- ▶ 1U 17" or 19" LCD console drawer
- ▶ 104-key keyboard with either touchpad or trackball
- ▶ Short depth design of 460mm and 500mm respectively
- ▶ New enhanced aesthetics with molded front handle
- ▶ Front USB port for device access (USB Hub KVM only)

Options

- S-Video + Composite (BNC)
- HDMI or DVI-D (either one)
- 2-post rack mounting brackets (**ORB-2.1**)
- DC power : 12V / 24V / 48V / 125V / 250V

Specifications

• LCD Panel

Manufacturer :	AUO	AUO
Size (diagonal) :	17" TFT	19" TFT
Max resolution :	1280 x 1024	1280 x 1024
Brightness (cd/m2) :	250	250
Backlight :	LED	LED
Colors :	16.7 M	16.7 M
Contrast ratio (typ) :	1000 : 1	1000 : 1
Viewing angle (H/V) :	170° x 160°	170° x 160°
Active area (mm) :	338 x 270	376 x 301
MTBF (hrs) :	30,000	30,000
Video input :	VGA	VGA

- **Speaker :** Built-in Dual Stereo Speakers
(HDMI only) 2W x 2

- **Power Input :** Auto-sensing 100 to 240VAC, 50 / 60Hz

• Power Consumption (single console)

Screen on :	Max. 25W
Power saving mode :	Max. 4W
Power button on :	Max. 1W

• Environmental

Operating temperature :	0 to 55°C degree
Storage temperature :	-20 to 60°C degree
Operating humidity :	20~90%, non-condensing
Storage humidity :	5 ~90%, non-condensing
Operating altitude :	16,000 ft
Non-operating altitude :	40,000 ft
Shock :	10G acceleration (11ms duration)
Vibration :	5~500Hz 1G RMS random vibration

- **Casing Color :** Black (RAL 9005)

• Regulatory

Safety :	cUL, FCC & CE certified
Environmental :	RoHS2 & REACH compliant

• Weight (single console) **Net** **Gross**

RKP117 :	12 kgs / 26 lbs	16.6 kgs / 36.5 lbs
RKP119 :	12.7 kgs / 27.9 lbs	17.3 kgs / 38.1 lbs

• Product Dimensions (single console)

RKP117 :	441.6 x 460 x 44 mm / 17.4 x 18.1 x 1.73 inch
RKP119 :	441.6 x 500 x 44 mm / 17.4 x 19.7 x 1.73 inch

• Packing Dimensions (single console)

RKP117 / 119 :	590 x 808 x 140 mm / 23.2 x 31.8 x 5.5 inch
----------------	---

 

Console Cable

CE-6


- 6 feet Combo KVM cable (bundle)
- VGA + USB or PS/2, server end
- DB15 (VGA, USB KB & MS), console port

Keyboard

Ge G keyboard integrated with touchpad

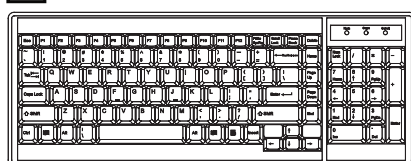

Gb G keyboard integrated with trackball

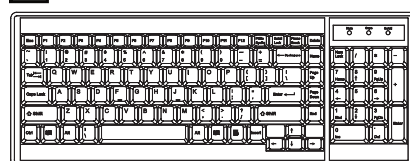

Supporting layouts

America					
	United States				
EMEA					
	United Kingdom	Germany	France	Spain	Norway
					
	Italy	Russia	Switzerland	Netherlands	Portugal
Asia					
	China	Japan	Korea	Arabia	Turkey


• Product Dimensions (with KVM)

RKP117 : 441.6 x 580 x 44 mm / 17.4 x 22.8 x 1.73 inch

RKP119 : 441.6 x 620 x 44 mm / 17.4 x 24.4 x 1.73 inch

• Packing Dimensions (with KVM)

RKP117 : 590 x 808 x 140 mm / 23.2 x 31.8 x 5.5 inch

RKP119 : 590 x 808 x 140 mm / 23.2 x 31.8 x 5.5 inch

• Weight (Net / Gross)

RKP117 : 13 kgs (28.6 lbs) 19 kgs (41.8 lbs)

RKP119 : 13.7 kgs (30.1 lbs) 19.7 kgs (43.3 lbs)

• Casing Color : Black (RAL 9005)
• Power Consumption with KVM integration : * For details, please refer to our KVM rear kit user manuals.

Screen on : Max. 55W

Power saving mode : Max. 34W

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-MUKVM-KIT.pdf
 stands for 17" or 19" LCD size.

Matrix Cat6 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	1	1	-	RKP11X - MUIP1613	RKP11X - MUIP3213
	1	1	2	-	RKP11X - MUIP1624	RKP11X - MUIP3224
	1	1	0	-	RKP11X - MU1602	RKP11X - MU3202
	1	2	0	-	RKP11X - MU1603	RKP11X - MU3203
	1	3	0	-	RKP11X - MU1604	RKP11X - MU3204

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-UKVM-KIT.pdf

Combo Cat6 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	0	1	RKP11X - UIP802	RKP11X - UIP1602	RKP11X - UIP3202
	1	1	0	RKP11X - U802	RKP11X - U1602	RKP11X - U3202
	1	0	0	RKP11X - U801	RKP11X - U1601	RKP11X - U3201

Cat6 KVM Dongle : DG-100S (VGA-USB) / DG-100 (VGA-PS/2) / DG-100SD (DVI-USB)

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-MKVM-KIT.pdf

Matrix DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	1	1	RKP11X - MIP813	RKP11X - MIP1613	-
	1	1	2	RKP11X - MIP824	RKP11X - MIP1624	-
	1	1	0	RKP11X - M802	RKP11X - M1602	-
	1	2	0	RKP11X - M803	RKP11X - M1603	-
	1	3	0	RKP11X - M804	RKP11X - M1604	-

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-SKVM-KIT.pdf

Combo DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	0	1	RKP11X - IP802	RKP11X - IP1602	-
	1	1	0	RKP11X - 802	RKP11X - 1602	-
	1	0	0	RKP11X - S801	RKP11X - S1601	-

Combo DB-15 KVM Cable : CE-6 / 10 / 15 (6, 10 or 15 ft)

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-DVIKVM-KIT.pdf

DVI-D KVM	Local	Remote	IP	12-port	-	-
	1	0	0	RKP11X - 1201D	-	-

DVI-D KVM Cable : CI-6 / 15 (6 or 15 ft)

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-USBKVM-KIT.pdf

USB Hub DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	0	1	RKP11X - IP802H	RKP11X - IP1602H	-
	1	1	0	RKP11X - 802H	RKP11X - 1602H	-
	1	0	0	RKP11X - 801H	RKP11X - 1601H	-

USB KVM Cable : CB-6 / 10 / 15 (6, 10 or 15 ft)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[96RMKVM-17V1C-A](#)