



RKP117 / 119 Single Console



Drawer Features & Display Benefits

- ▶ 1U 17" or 19" LCD console drawer
- ▶ 104-key keyboard with either touchpad or trackball
- ▶ Short depth design of 460mm and 500mm respectively
- ▶ New enhanced aesthetics with molded front handle
- ▶ Front USB port for device access (USB Hub KVM only)
- ▶ 2 post rack mounting available

Options

- S-Video + Composite (BNC) or Audio input
- HDMI or DVI-D (either one)
- 48V, 24V or 12VDC power

Specifications

• LCD Panel

Manufacturer :	AUO	AUO
Size (diagonal) :	17" TFT	19" TFT
Max resolution :	1280 x 1024	1280 x 1024
Brightness (cd/m2) :	250	250
Backlight :	CCFL	LED
Colors :	16.7 M	16.7 M
Contrast ratio (typ) :	1000 : 1	1000 : 1
Viewing angle (H/V) :	160° x 160°	170° x 160°
Active area (mm) :	338 x 270	376 x 301
MTBF (hrs) :	50,000	30,000
Signal input :	VGA	VGA

• Casing Color :

Black (RAL 9005)

• Weight (Single console)

Net :	12 kgs (26 lbs)	12.7 kgs (27.9 lbs)
Gross :	16.6 kgs (36.5 lbs)	17.3 kgs (38.1 lbs)

• Environmental

Operating :	0 to 50°C Degree
Storage :	-5 to 60°C Degree
Relative humidity :	5~90%, non-condensing
Shock :	10G acceleration (11 ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• Regulatory

Safety :	cUL, FCC & CE certified
Environmental	RoHS2 & REACH compliant

• Power

Input :	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption :	Max. 48 Watt, Standby 5 Watt

• Product Dimensions (Single console)

RKP117 :	441.6 x 460 x 44 mm / 17.4 x 18.1 x 1.73 inch
RKP119 :	441.6 x 500 x 44 mm / 17.4 x 19.7 x 1.73 inch

• Packing Dimensions (Single console)

RKP117 / 119 :	590 x 808 x 140 mm / 23.2 x 31.8 x 5.5 inch
----------------	---

Console Cable

 

CE-6

6 feet Combo KVM cable (bundle)


- VGA + USB or PS/2, server end
- DB15 (VGA, USB KB & MS), console port

Keyboard

Ge G keyboard integrated with touchpad

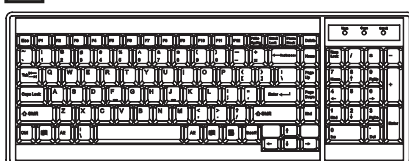

Gb G keyboard integrated with trackball

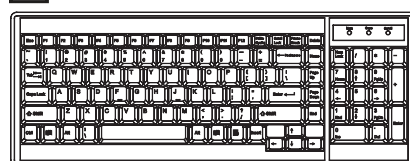

Supporting layouts

America		United States			
EMEA					
	United Kingdom	Germany	France	Spain	Norway
	Italy	Russia	Switzerland	Netherlands	Portugal
Asia					
	China	Japan	Korea	Arabia	Turkey

- Weight (Net / Gross)

RKP117 : 13 kgs (28.6 lbs)	19 kgs (41.8 lbs)
RKP119 : 13.7 kgs (30.1 lbs)	19.7 kgs (43.3 lbs)

- **Casing Color :** Black (RAL 9005)

RKP119 : 13.7 kgs 19.7 kgs
(30.1 lbs) (43.3 lbs)

X stands for 17" or 19" LCD size.

Matrix Cat6 KVM 	Local	Remote		8-port	16-port	32-port
	1	1	1	-	RKP11X - MUIP1613	RKP11X - MUIP3213
	1	1	2	-	RKP11X - MUIP1624	RKP11X - MUIP3224
	1	1	0	-	RKP11X - MU1602	RKP11X - MU3202
	1	2	0	-	RKP11X - MU1603	RKP11X - MU3203
	1	3	0	-	RKP11X - MU1604	RKP11X - MU3204

Combo Cat6 KVM 	Local	Remote		8-port	16-port	32-port
	1	0	1	RKP11X - UIP802	RKP11X - UIP1602	RKP11X - UIP3202
	1	1	0	RKP11X - U802	RKP11X - U1602	RKP11X - U3202
	1	0	0	RKP11X - U801	RKP11X - U1601	RKP11X - U3201

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-MKVM-KIT.pdf

Matrix DB-15 KVM 	Local	Remote		8-port	16-port	32-port
	1	1	1	RKP11X - MIP813	RKP11X - MIP1613	-
	1	1	2	RKP11X - MIP824	RKP11X - MIP1624	-
	1	1	0	RKP11X - M802	RKP11X - M1602	-
	1	2	0	RKP11X - M803	RKP11X - M1603	-
	1	3	0	RKP11X - M804	RKP11X - M1604	-

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-SKVM-KIT.pdf

Combo DB-15 KVM 	Local	Remote		8-port	16-port	32-port
	1	0	1	RKP11X - IP802	RKP11X - IP1602	-
	1	1	0	RKP11X - 802	RKP11X - 1602	-
	1	0	0	RKP11X - S801	RKP11X - S1601	-

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-DVIVKM-KIT.pdf

DVI-D		Local	Remote		12-port	-	-
KVM		1	0	0	RKP11X - 1201D	-	-

DVI-D KVM Cable : CI-6 / 15 (6 or 15 ft)

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-USBKVM-KIT.pdf

USB Hub DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	0	1	RKP11X - IP802H	RKP11X - IP1602H	-
	1	1	0	RKP11X - 802H	RKP11X - 1602H	-
	1	0	0	RKP11X - 801H	RKP11X - 1601H	-

USB KVM Cable : CB-6 / 10 / 15 (6, 10 or 15 ft)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[96RMKVM-19V1C-A](#)