

ACP-1010

1U Rackmount Chassis for Full-size SHB/SBC or ATX/MicroATX Motherboard



CE FCC

Features

- Supports full-size SHB/SBC or ATX/MicroATX motherboards
- LED indicators for power, HDD, temperature, fan, LAN1 and LAN2
- Supports up to 2 expansion slots in BP version, and 1 expansion slot via riser card in MB version
- Supports both 250W/350W Flex ATX/PFC power supplies


Specifications

Driver bay		External	Internal
	Slim Optical Disk Drive	1	-
	3.5"	1	1*
	2.5"	-	2*
Cooling	Fan	BP: 4 (4 cm/24 CFM x 3 + 15 CFM x 1) MB: 2 (4 cm/24 CFM each)	
Front I/O Interface	USB 2.0	2	
Miscellaneous	Notification LEDs	System: Power, HDD, Temperature, Fan, LAN1 and LAN2	
	Control	Power switch, system reset & alarm reset button	
	Rear panel	One 9-pin D-Sub opening	
Environment	Operating		Non-Operating
	Temperature	0 ~ 40 °C (32 ~ 104 °F)	-20 ~ 60 °C (-4 ~ 140 °F)
	Humidity	10 ~ 85% @ 40 °C, non-condensing	10 ~ 95% @ 40 °C, non-condensing
	Vibration (5 ~ 500 Hz)	0.5 Grms	2 Grms
	Shock	10 G (with 11 ms duration, half sine wave)	
Physical Characteristics	Dimensions (W x H x D)	480 x 44 x 497 mm (19" x 1.7" x 19.6")	
	Weight	8 kg (17.6 lb)	

* Internal driver bay can choose 1 x 3.5" or 2 x 2.5"

* ACP-1010 supports up to CPU 65W under 35 °C for thermal concern.

Front View

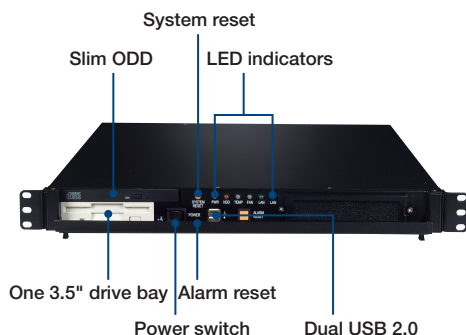

Back View



ACP-1010BP




ACP-1010MB


Dimensions

Unit: mm [inch]

ACP-1010BP

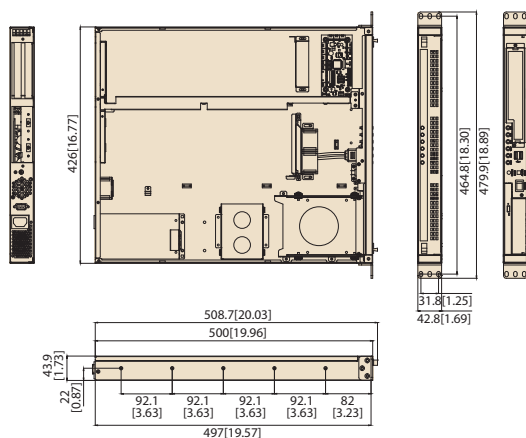

ACP-1010MB

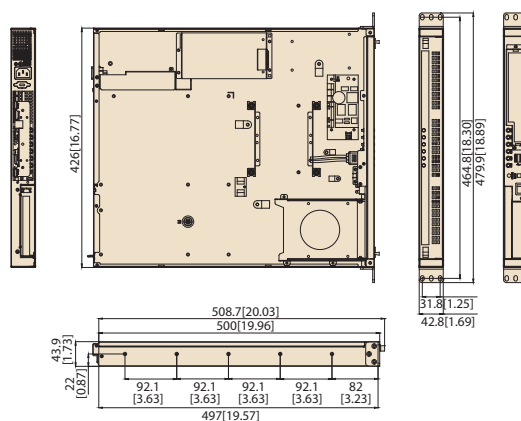

Ordering Information

Part Number	Description
Backplane Version	
ACP-1010BP-00BE	BP version W/O PSU
Motherboard Version	
ACP-1010MB-00BE	MB version W/O PSU

* ACP-1010MB does not support AIMB-763, 542, 562, 564 and AIMB-786 because the height of the audio connector is over 1U.

Power Supply Options

(For detailed power supply specs, please refer to Chapter 13)

Part Number	80 Plus Bronze	Wattage	Type	Input
PS8-250FATX-XE	Bronze	250W	Single	AC 100 ~ 240 V (full range)
PS8-350FATX-XE	Bronze	350W	Single	AC 100 ~ 240 V (full range)

Spare Parts

Part Name	Description
2130007889S000	Filter 170 x 32 x 5 mm for ACP-1010

Optional Accessories

Part Name	Description
96CB-SATAPOWER-6P2	SATA power wire 6-pin to big 4-pin (for slim ODD)
I/O shield	
1960055954T000	I/O shield for AIMB-706/705/701/781/782/581
1960048353T000	I/O shield for AIMB-767/769/780/566/580
1960069682N001	I/O shield for AIMB-784
1960069666N101	I/O shield for AIMB-785

Backplane Options

Part Name	Slot	CPU Card
PICMG 1.3		
PCE-5B03V-01A1E	One CPU, one PCIe x16, one PCI (32-bit/33MHz)	PCE-5000 Series
PCE-5B03V-00A1E	One CPU, one PCIe x16, one PCIe x4	
PCE-7B03V-01A1E	One CPU, one PCIe x8, one PCI	PCE-7000 Series
PCE-7B03V-00A1E	One CPU, two PCIe x8	
PICMG 1.0		
989K610302E (PCA-6103P2V-0A2E)	One CPU,2 PCI (320bit/33MHz)	PICMG 1.0 Full-Size SBC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[ACP-1010MB-00BE](#) [ACP-1010BP-00BE](#)