

AIM-P701

Multi-Functional Smart Cradle for AIM-37 Mobile POS



Features

- Compact and stylish cradle for AIM-37 Mobile POS
- 180° swivel design can easily turn the tablet to the other side
- Optional embedded high speed thermal receipt printer with LED indicators, feed paper button, and auto paper cutter
- Supports 5V/3A high speed charging to AIM-37 Mobile POS via Pogo Pin
- Supports multiple I/Os : 2 x USB 2.0 Type A; 2 x COM Ports via RJ48; optional RJ11 for Cash Drawer

 

Specifications

Model Name		AIM-P701A0	AIM-P701B0
Supported OS		Windows 10 IoT Enterprise Android 6.0	
Swivel		180° rotational	
Pogo Pin		USB 2.0 5V/3A Charger	
Thermal Printer	Paper width	80mm/58mm	N/A
	Paper roll	70mm diameter	
	Printing speed	200mm / s	
	Paper cutter	Auto Cut	
	Buttons	Open Door; Feed Paper	
	LEDs	Power indicator; error indicator	
I/O Port		1 x DC IN 2 x USB 2.0 Type A 2 x COM Port (RJ48)	
		1 x Cash Drawer (RJ11)	N/A
Dimensions		151 x 152 x 318 mm	
Environment	Operating Temperature	0 ~ 40° C	
	Storage Temperature	-10 ~ +60° C	
	Operating Humidity	5% ~ 95%, non-condensing	

Ordering Information

P/N	Description
AIM-P701A0	Charging , USB x 2, COM (RJ48 type) x 2, RJ11 x 1 80mm Thermal Printer, Auto cutter
AIM-P701B0	Charging , USB x 2, COM (RJ48 type) x 2


Fully-Integrated I/O

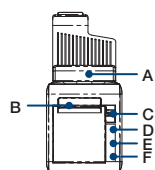

- A: Tablet Holder
- B: Auto Cutter
- C: Open Door
- D: Power Indicator
- E: Error Indicator
- F: Out of paper Indicator
- G: DC Jack
- H: USB Type A
- I: COM Port (RJ48)
- J: Cash Drawer (RJ11)

Dimensions

Unit: mm

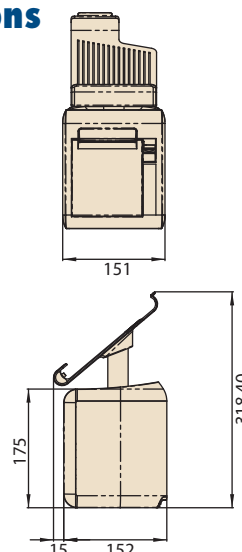

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[AIM-P701A0](#) [AIM-P701B0](#)