

# AMT-1021N-D25W1

21.5" FHD Monitor



## Features

- 21.5" TFT-LCD panel with LED backlight for 20% power saving and environment protection
- Stylish White with VESA Compatibility
- Dual Signal interface with VGA & DVI
- 0° C ~ 40° C range operating temperature
- Slim housing design and widescreen format
- Built-in speakers



## Introduction

One of the most versatile monitor, AMT-1000, provides great picture quality with a built-in power saving system. It's perfectly designed to fit with Advantech AMiS Computerized Medical Cart. Model Number AMiS-60 and AMiS-50.

(This model doesn't include battery converter and monitor stand)


## Specifications

Display	Model	
	Size	21.5" TFT-LCD
	Resolution	1920 x 1080
	View Angel	85°/85° (H) 80°/80° (V)
	Brightness	250 (cd/m <sup>2</sup> )
	Color Support	16.7M
	Contrast Ratio	1000:1
	Response Time	5 [msec]
	Backlight Life	30000 (hrs)
Environment	Operating Temperature	0~40°C
	Storage Temperature	-20°C~ 60°C
	Humidity	Operating: 20 ~ 80% Non Operating: 10~90%
	Vibration	Vibration Frequency: 5~200Hz, Acceleration: 1.038GRMS, Test Duration: 30minutes per axis
System	I/O	VGA x1; DVI-D x1;
	OSD	Menu Functions: Brightness, Contrast, Screen Setting, Color Temp, VGA/DVI, Recall, Auto Adjust
	Power Consumption	25W (typ) < 30W(MAX)
	Power Supply Accessory (Optional)	Part Number : 96PSA-A60W12R1-1 Description: Adapter AC to DC 100-240V 60W 12V
	EMC Compliance	CE, FCC

# AMT-1021N-D25W1

21.5" WXGA Monitor

## Drawing

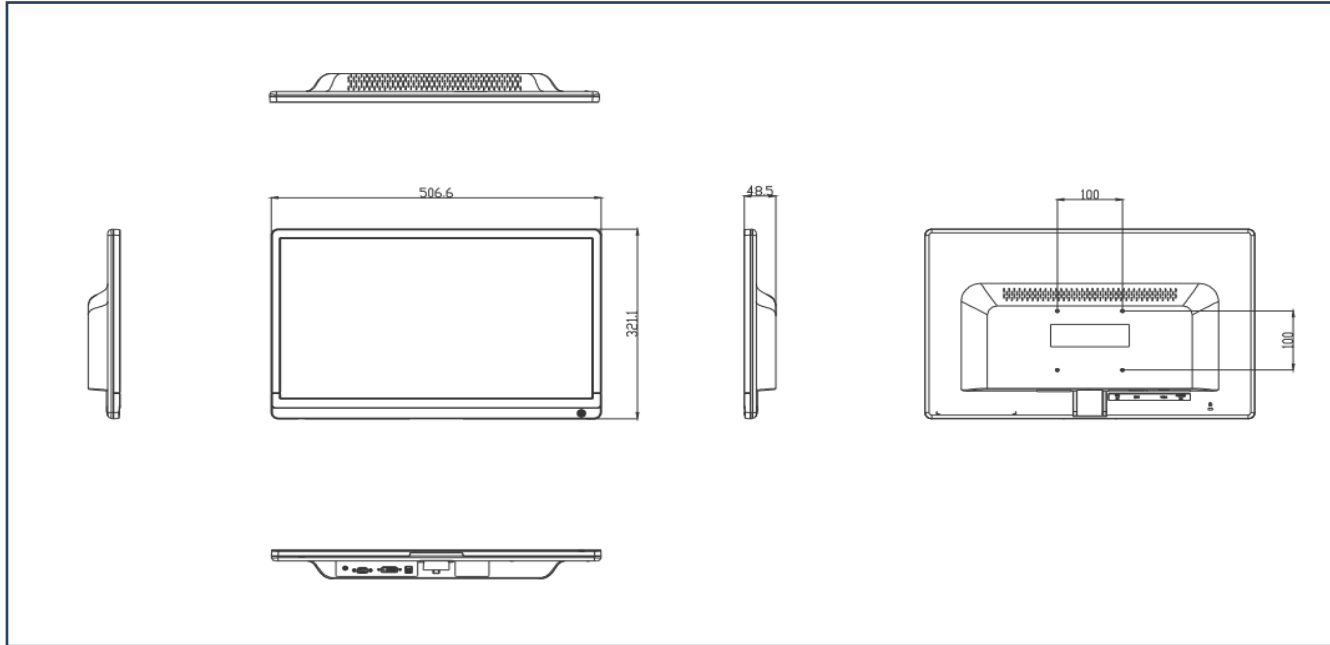

**ADVANTECH** Peripheral Allied Procurement Services - Global Sourcing Local Supports -

All product specifications are subject to change without notice.

Last update: 08-20-2015

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[AMT-1021N-D25W1](#)