

AMiS-30EP Pole Cart



Features

- IPX1-rated protection from water ingress
- Built-in cable management minimizes trip hazard
- Tilt-resistant base with sturdy center pole
- Multi-purpose utility basket for storage
- 4" casters and round tread wheels ensure easy portability
- Can be rapidly assembled

Specifications

Category	Attribute	AMiS-30E
Base Cart	Footprint	20" x 19" (512 x 482 mm)
	Height	1400 mm
	weight	15kg/33 lb
	Casters	125 mm x 125 mm (Anti-Static Medical casters, two locking, two non-locking)
	Height Adjustment Range	Fix
	Display Holder	Standard VESA Mount (VESA 75/75; VESA 100/100); Weight capacity: max. 18lb/8 kg
	Basket	L280 x W140 x H160mm
	Handle space	200 x 102mm
Optional	Battery Type	Lithium-ion
	Battery Capacity	Total: 270wh (90wh x 3)
	Power Input Voltage	100-240V _{AC} , 50-60Hz
	Battery Life SPAN	Capacity 70%, 500cycles or 1 years (Whichever occurs first)
	Battery Charge Time	<3Hr 200Wh
	Battery Runtime (Depends on system configuration)	Depends on system configuration.3-5hours
	Scalable BAT	90x3 =270Wh/sets
	Power Output	DC 12V/19V/24V
	Accessory Extend Used	Dovetail (optional); Right/Left
Certification		IPX1


Computer System Section

Category	Attribute	
W213L	CPU	Intel Core i5-7300U 2.6GHz
	Memory	4 GB DDR4 SODIMM
	Storage	2.5" SATA SSD 128GB
	Display	21.5" 1920 x 1080 FHD P-Cap Touch Screen
	WiFi	Intel® Dual Band Wireless-AC 8265
	Speaker	1.5 Watt x 2
	IP Rating	Front Panel: IP65 Entire Computer: IPX1
	Operating System	Win10 IoT

AMIS-30EP Pole Cart


Dimensions

Unit: mm

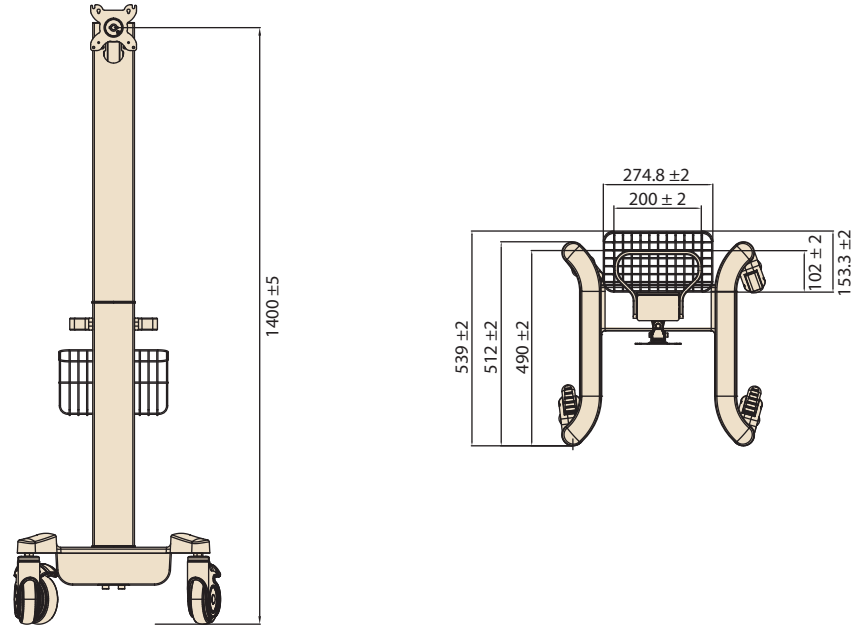

Order Information

Part Number	Product Description
AMIS-30E-1P1-Z3NE	Pole cart with basket (without monitor)

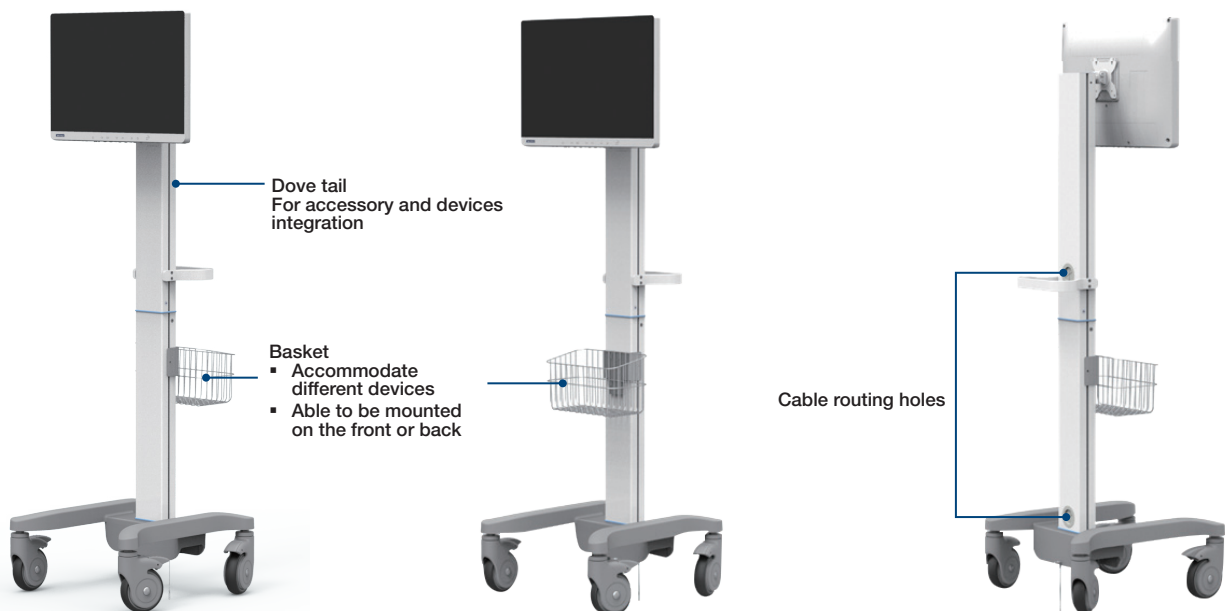

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[AMIS-30E-1P1-Z3NE](#)