


ASMB-923

**Dual LGA 2011-R3 Intel® Xeon®
E5-2600 v3/v4 EATX Server Board with
8 DDR4, 4 PCIe x16+ 2 PCIe x8,
4 USB 3.0, IPMI**

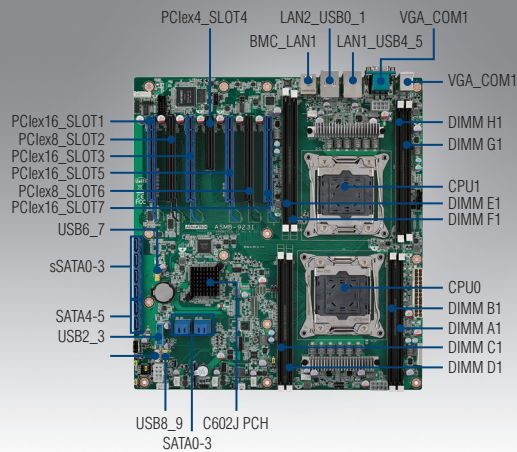


Features

- EATX server board with dual Xeon® E5-2600 v3/v4 processor, 8 DIMMs 256 GB memory capacity
- DDR4 2400 MHz RDIMM up to 256 GB
- Four PCIe x16 slots (Gen3) + two PCIe x8 slots (Gen3.0) and one PCIe x4 (Gen2.0)
- 0 ~ 40 °C ambient operating temperature range

Specifications

Form Factor	Extended ATX form factor				
Processor System	Socket	Intel LGA 2011-R3			
	CPU type	Intel® Xeon® E5-2600 v3/v4 dual processor (CPU cooler should be purchased separately and TDP up to 160W) Intel® Xeon® E5-1600 v3/v4 Series (1S conditional support, please contact to Advantech application engineer)			
Core Logic	Chipset	Intel C612 chipset			
	Total slots	8 (Quad Channel)			
Memory	Capacity	Maximum 256 GB ECC RDIMM			
	Memory type	DDR4 ECC-REG 2400/2133/1866/1600/1333 MHz DIMM			
	Memory size	1 GB, 2 GB, 4 GB, 8 GB, 16 GB, 32 GB			
Expansion Slots	Total PCI/PCI-X/PCIe slots	7			
	Slot location 1	PCIe x16 slot (x16 link), signal from CPU1			
	Slot location 2	PCIe x16 slot (x8 link), signal from CPU1			
	Slot location 3	PCIe x16 slot (x16 link), signal from CPU1			
	Slot location 4	PCIe x8 slot (x4 link), signal from PCH			
	Slot location 5	PCIe x16 slot (x16 link), signal from CPU0			
	Slot location 6	PCIe x16 slot (x8 link), signal from CPU0			
Graphics	VGA	Aspeed AST2400/1400 64 MB			
	IDE controller	-			
Storage	SATA controller	Intel C610: 10 SATA3 6 Gb/s ports Intel Rapid Storage Technology (for Windows only) (SATA0-SATA5 and sSATA0-sSATA3 Supports software RAID 0, 1, 10 & 5)			
	SAS controller	-			
Networking	GbE LAN	2 x Intel I210AT			
Onboard I/O Connector	Floppy connector	-			
	PSU connector	24-pin SSI power connector + 8-pin SSI 12 V power connector + 8-pin SSI 12 V power connector			
	USB connector	2 (supports 4 USB port), 1* Type-A , 1* USB3.0 20pin header (supports 2*USB 3.0 port)			
	Fan header	5 x 4-pin			
	SMBus	1			
	Chassis intruder	1			
	Front LAN LED	2			
	Audio Header	1			
	Serial port header	1			
Rear I/O Connector	External serial port	1			
	External USB port	4 (2*USB2.0 + 2*USB3.0)			
	VGA port	1			
	RJ-45	3 (1 port dedicated for IPMI function)			
	PS/2 KB/mouse	1			
	Infiniband	-			
Management Solution	Software	-			
	Out of band remote management	Yes (ASMB-923I sku only)			
Monitoring	CPU temperature	Yes			
	System Monitoring	Yes			
Watchdog Timer	Output	System reset			
	Interval	Programmable 1 ~ 255 sec/min			
Power Requirement	Power On	3.3V	5V	12V	5Vsb -12V
		1.69A	1.00A	17.42A	0.05A 0.01A
Environment	Operating	Non-operating			
	Temperature	0 ~ 40 °C, depends on CPU speed and cooler solution			
	Humidity	10% ~ 95%			
Physical Characteristics	Dimension (L x H)	304.8 x 330.2 mm (12" x 13")			

Block Diagram

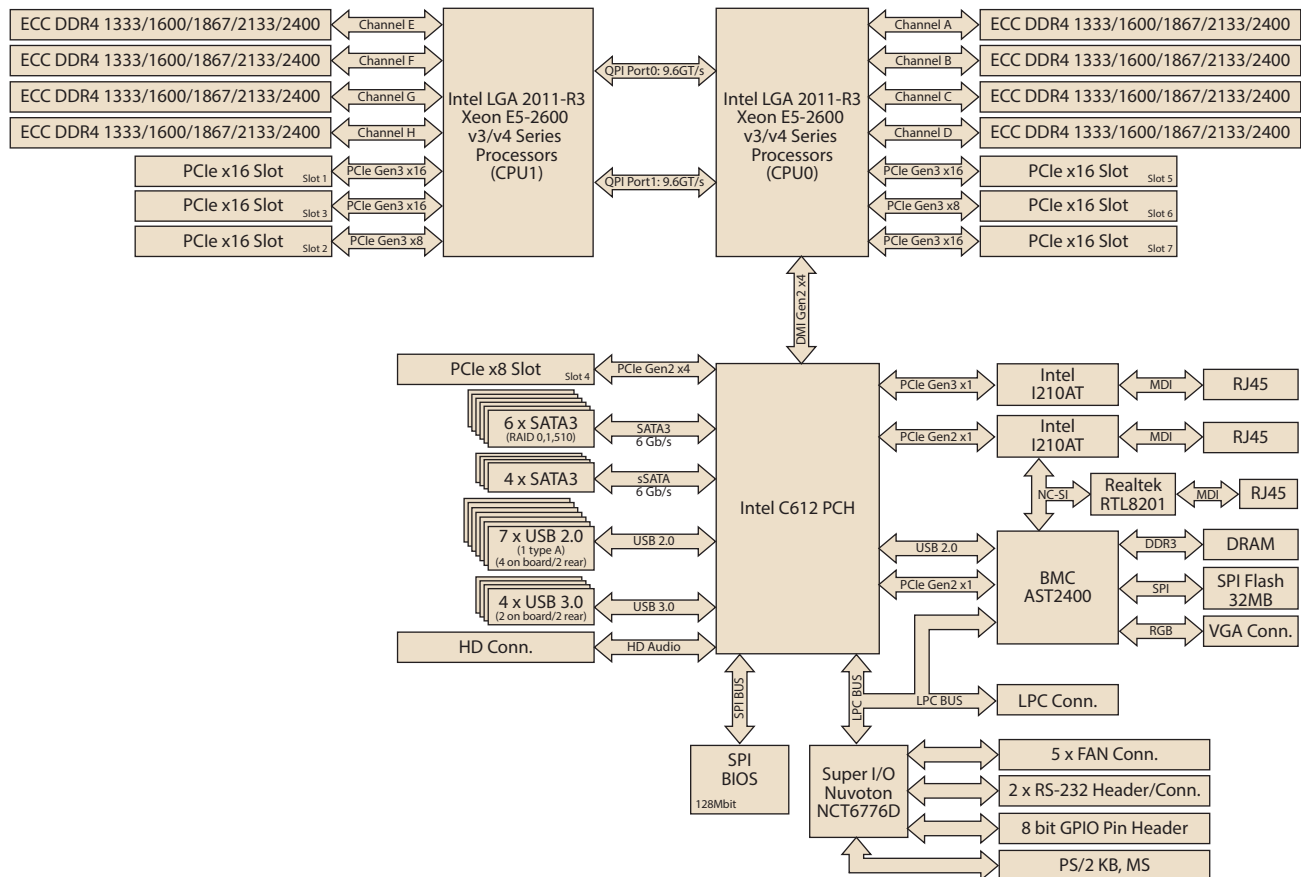

Ordering Information

Part Number	Chipset	Memory	GbE LAN	IPMI	Graphics
ASMB-923-00A1E	C612	DDR4 RDIMM	2	-	AST 1400
ASMB-923I-00A1E	C612	DDR4 RDIMM	2	Yes	AST 2400

Packing List

Part Number	Description	Quantity
2066923I01	Driver CD	x 1
2006923I10	Startup manual	x 1
1700003194	SATA data cables	x 2
1703150102	SATA power cables	x 2
1700019748	CPU power cable(8P)	x 2
1960052312T010	I/O shield	x 1

Optional Accessories

Part Number	Description
PCA-AUDIO-HDA1E	HD Audio-card
PCA-TPM-00B1E	TPM 2.0 Module by LPC
1960057226N001	LGA-2011 square CPU heatsink for 1U chassis (95W)
1960055362N001	LGA-2011 square CPU cooler for 2U/4U chassis (145W)
1960065684N011	LGA-2011 square CPU cooler for 4U chassis (160W)
1700028025-01	Dual port USB cable (45 cm) with bracket
1700028042-01	Four port USB cable (45 cm) with bracket
1701090401	COM port cable with bracket
19Z0000406T000	1U chassis IO shield
968EMLSAP2	SUSIAccess Pro 3.0

I/O View



ASMB-923-00A1E



ASMB-923I-00A1E

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[ASMB-923I-00A1E](#) [ASMB-923-00A1E](#)