

ASR-1400

4U 24-bay Reliable Disk Expansion Enclosure to Fit Industrial Applications



Features


- Support 24x hot-swap 2.5"/3.5" SATA/SAS 6Gb/s drives
- SES enclosure management and smart fan control
- Two 6Gb/s SAS host ports, storage daisy chain support
- High efficiency (80+) redundant power supplies
- Optional to enable two SAS host ports for maximum performance

Specification

System	Form Factor	4U-24Bay	
	Number of Drives	24-Bays (2.5"/3.5")	
	Drive Type	SATA/SAS 6Gb/s or 3Gb/s	
	SAS Expansion Port	2 x 6Gb/s SAS 4x wide ports	
	Smart Fan Control	Yes (smart fan control for both cpu & sys fan)	
Power Supply	Power Output Wattage	875W Redundant Power	
	Input Range	AC 100-240V	
Mechanical	Dimension	699 x 432 x 176 (mm)	
	Weight	41 kg (without hard drives)	
Environmental	Temperature	Operation	Non-operation
		0° C ~ 40° C (32° F ~ 104° F)	-20° C ~ 60° C (-4° F ~ 140° F)
	Humidity	10% ~ 85% @ 40° C, non-condensing	10% ~ 95% @ 40° C, non-condensing
Misc	Notification LED	Power Status, System Fail	

Dimensions


Unit: mm

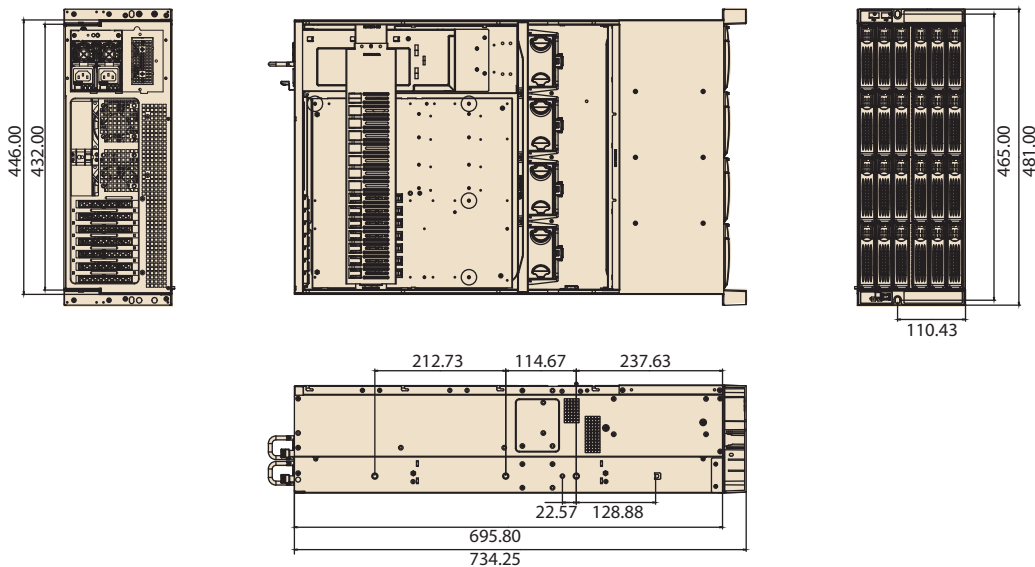


Order Information

Advantech P/N	Description
ASR-1400-24A1E	4U 24-Bay JBOD Expansion Enclosure

Front View

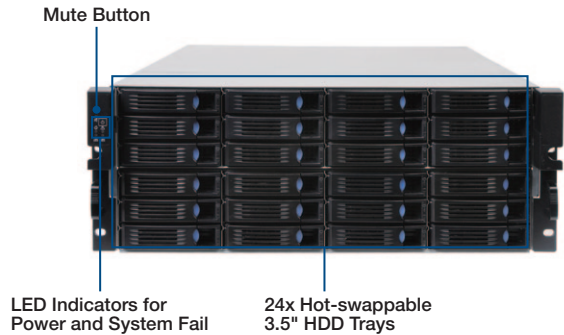

Rear View

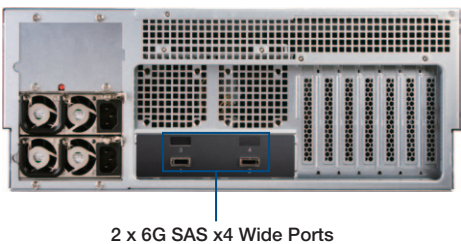

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[ASR-1400-24A1E](#)