


AVAS-402

Medical VMS/Recorder and Computing Platform

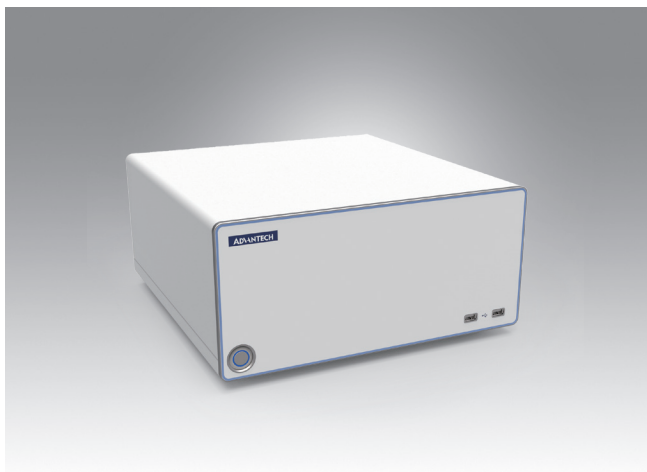


Features

- Multi channels are supported to record 4K and FHD medical videos simultaneously
- H.265 recording technique enables to save high quality video while conserving storage capacity
- Video source can be previewed with 4Kp60 to make medical video accessible
- An open SDK and API enable user to integrate the product into environment or workflow management system
- Support Windows 10/Linux Kernel Operation System, FCC/CE/MDD 60601/UL/CB/CCC Certifications
- Support windows video recording and video management software
- Support Intel® Xeon®/6th & 7th Gen Core™ i7/i5/i3 processor with Q170/C236/H110 chipset
- Supports Software RAID 0,1,5,10, TPM 1.2/2.0 (optional)

Specifications

| | | |
|--------------------|----------------------------------|--|
| Video | Input Resolution (Capture Card) | Up to 4K UHD |
| | Output Resolution (Graphic Card) | Up to 4K UHD |
| | Compression Format | MPEG2 H.264, H265 |
| Audio | Audio | 2 (Mic-in/ Line-out) (Mic-in could be configured as "Line-in" under Win OS.) |
| | CPU | Intel i7-7700 / i5-7500 / Xeon E3-1275 v6 |
| System | Memory | 16G |
| | HDD | 1T |
| I/O | Capbure I/O | 4Kp60: HDMI 2.0 in FHD (max): Y/PbPr, CVBS, S-Video, SDI, HDMI, DVI-I (can be optional) |
| | Video Display I/O | DVI, Display Port, HDMI (can be optional) |
| | Ethernet | RJ-45 x 2 |
| | Usb Host | 10 (6 x USB 3.0, 4 x USB 2.0) |
| | Audio Out/In | 2 for Audio out/in 3.5mm stereo jack connectors |
| | Rs232 | RS-232 x 1 |
| Power | | 500W Medical Internal PSU, 100-240V AC in |
| Certification | | FCC/CE/MDD 60601/UL/CB/CCC |
| Environmental | Operation Temperature | 0 °C to +40 °C |
| | Storage Temperature | -10 °C to +50 °C |
| Dimension & Weight | | 320 x 329 x 145 mm, 10Kg |
| SDK Main Function | | Streaming control, capture, recording, streaming, playback, editing, tools |

I/O

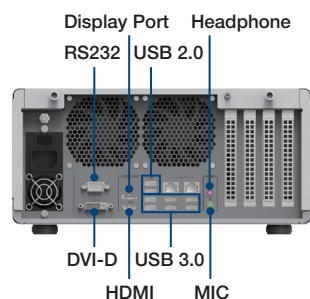

Ordering Information

| Part Number | Description |
|--------------------|--|
| AVAS-402-MVAB-0A00 | Recorder/4Kp60+FHDp60/i7-7700/16GB/1TB |
| AVAS-402-MVAB-0A02 | Recorder/FHDp60/i5-7500/16GB/1TB |
| AVAS-402-XNAB-0A00 | BoxPC/i7-7700/16GB/1TB |
| AVAS-402-XNAB-0A01 | BoxPC/i7-7500/16GB/1TB |

Optional items

| Part Number | Description |
|----------------|--|
| AVAS-OPAC-1001 | FHD 1080p PTZ Camera |
| AVAS-OPAC-1010 | Unified Communication USB Speakerphone |
| AVAS-OPAC-2001 | GTX1650 4G PCIeX16 DVI+HDMI Display Card |
| AVAS-OPAC-2004 | DVP-7011UHE 1ch 4K UHD Capture Card |
| AVAS-OPAC-2005 | DVP-7611HE 1ch 1080p FHD Capture Card |
| AVAS-OPAC-6001 | Recorder Software License |
| AVAS-OPAC-6003 | Video Conference Software License |
| 1702002600 | Power Cord UL 3P 10A 125V 183cm |
| 1702002605 | Power Cord EU 3P 10A 250V 183cm |

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[AVAS-402-MVAB-0A00](#)