


BB-9PAMF1
BB-9PAMF3
BB-9PAMF6

BB-9PAMF10
BB-9PAMF15
BB-9PAMF25

DB9M to DB9F Serial Cables

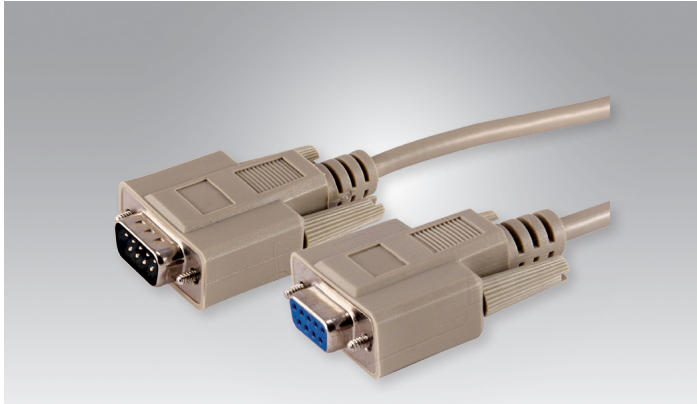

Features

- Fully molded backshell with strain relief for extra protection
- 28 AWG stranded conductors for flexibility
- Thumbscrews for tool-less termination
- DB9 male to DB9 female
- REACH, RoHS-3 (2011/65/EU amended by 2015/863/EU)


Introduction

These ready-to-use serial cables feature fully molded backshells, strain relief protection, and thumbscrews. Suitable for connecting 9-pin serial devices to laptops, computers and more. Choose from 0.3 to 7.6 meter lengths (1 to 25 ft).

Ordering Information

Model No.	Description	Length
BB-9PAMF1	Serial Cable, DB9 Male to DB9 Female	0.3m (1 ft)
BB-9PAMF3	Serial Cable, DB9 Male to DB9 Female	0.9m (3 ft)
BB-9PAMF6	Serial Cable, DB9 Male to DB9 Female	1.8m (6 ft)
BB-9PAMF10	Serial Cable, DB9 Male to DB9 Female	3.1m (10 ft)
BB-9PAMF15	Serial Cable, DB9 Male to DB9 Female	4.6m (15 ft)
BB-9PAMF25	Serial Cable, DB9 Male to DB9 Female	7.6m (25 ft)

Dimensions

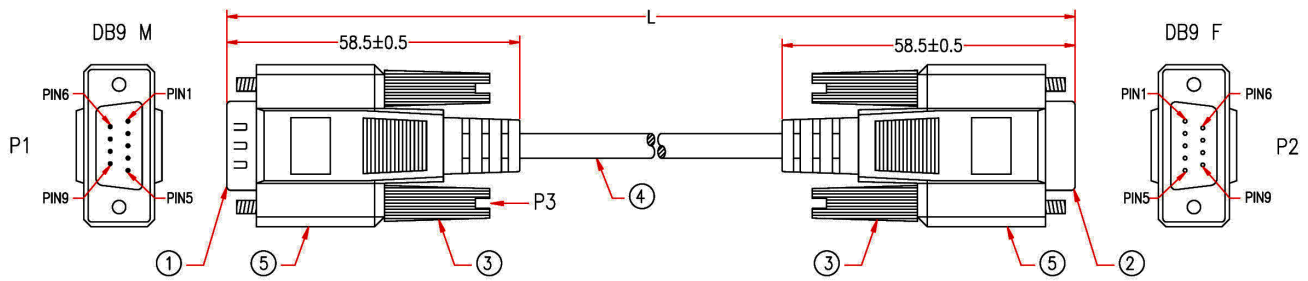

P1	1006	P2
1	_____	1
2	_____	2
3	_____	3
4	_____	4
5	_____	5
6	_____	6
7	_____	7
8	_____	8
9	_____	9
SHIELD	_____	SHIELD

*NOTE: All relevant materials are complied with RoHS directive .

5	BLACK PVC TUBE #3.0*22mm
	ALUMINUM FOIL 33*65mm
	MOLDED PE COLOR TRANSPARENT
	MOLDED PVC BEIGE
4	NON-UL 9C 28AWG, ALUM-MYLAR FOIL SHIELDING WITH DRAIN WIRE, OD 5.0mm, JACKET BEIGE, DRAWING NO. EMAL2809C-051
3	MOLDED THUMBSCREW #4-40, LENGTH 46.5mm, BEIGE
2	DB9 FEMALE, GOLD FLASH ON CONTACTS, BLUE INSULATOR
1	DB9 MALE, GOLD FLASH ON CONTACTS, BLUE INSULATOR

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[BB-9PAMF10](#)