

## GSM/UMTS ANTENNA

Antenna UMTS/GSM Magnetic  
U30,3 dBi, SMA(m), RG174/3m

BB-AO-AUMTS-M3S


### BENEFITS

- Low VSWR
- Easy installation
- Omnidirectional - suitable for moving devices



Technology	GSM/UMTS
Frequency bands	900/1800/1900/2100 MHz
Bandwidth	-
Gain	3 dBi
VSWR	<2.0:1
Impedance	50 Ohm
Directivity	Omnidirectional
Beam angle	H 360° V 30°
Polarization	Vertical
Maximum input power	10 W
Power voltage	-
Dimensions	214 x Ø27 mm
Weight	46.32 g
Operating temperature	-40 to +85 °C
Execution	External
Method of attachment	Magnetic
Cable type	RG174/U
The cable length	3 m
Connector type	SMA(m)

## DRAWING

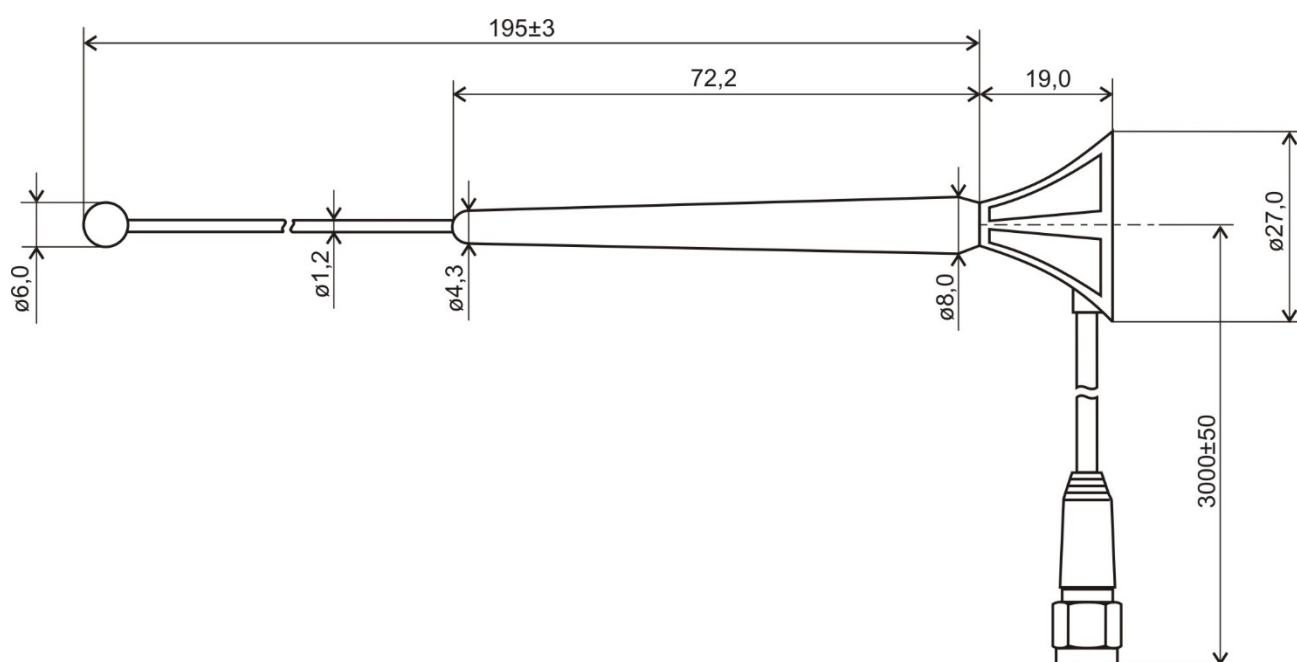

UNIT: mm

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[BB-AO-AUMTS-M3S](#)