

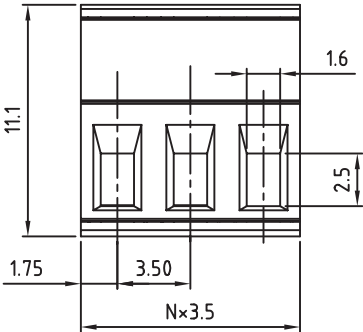


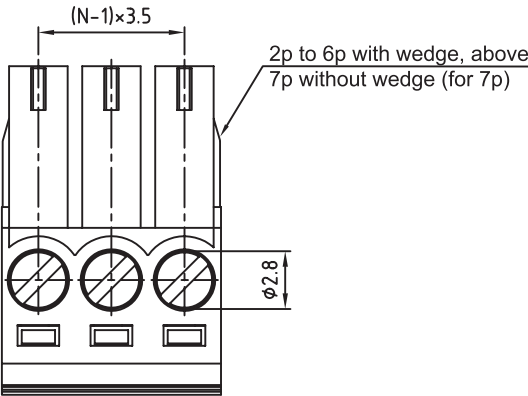

N=Number of contacts

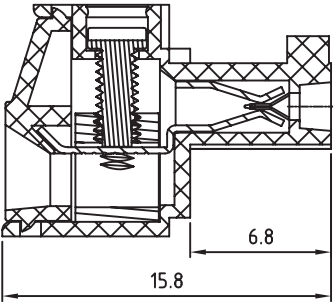

TECHNICAL CHARACTERISTICS

MATERIAL
INSULATOR: PA 66
FLAMABILITY RATING: UL94-V0
COLOR: GREEN
METAL HOUSING: BRASS (CuZn)
TERMINAL SCREW: STEEL ZINC PLATING
TERMINAL SCREW SLOT TYPE: "-"
WIRE GUARD: PhBz TIN PLATED

ENVIRONMENTAL
OPERATING TEMPERATURE: -40 UP TO 105°C
COMPLIANCE: LEAD FREE AND ROHS

ELECTRICAL	cULus	VDE
CURRENT RATING:	10A	10.5A
WORKING VOLTAGE:	300VAC	300VAC
WITHSTANDING VOLTAGE:	1.6KV	2.5KV
CONTACT RESISTANCE: □	20 mOhm max	

 
MECHANICAL
SOLID WIRE: 26-16 AWG / 0.13-1.5MM²
STRANDED WIRE: 26-16 AWG / 0.13-1.5MM²
TORQUE: 3.0Lb-In / 0.34Nm

 
WIRE STRIPE LENGTH: 6-7MM
SCREW: M2.0
PITCH: 3.5MM

PACKAGING: BOX

SERIE 3611

CERTIFICATION



RoHS Compliant					PROJECTION: 	GENERAL TOLERANCE .X = +/- 0.2 .XX = +/- 0.15		
G								
F								
E								
D								
C					APPROVAL: RJ	UNIT: MM	DESCRIPTION: SERIE 3611 - 3.50MM VERTICAL CABLE ENTRY PLUG 1.5MM² WIRES WR-TBL	SIZE A4
B								
A□	31-OCT-08□	PDF□ □	JP					
REV	DATE	FILE	BY					
							WERI PART NO: 691 361 100 0xx	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[BB-CON-CR4P-TB](#)