

BB-WTJ-10-36-TT

J-type Thermocouple - washer, ungrounded



Features

- J-type ungrounded thermocouple
- #10 or M4.5 screw mounting
- 20 AWG solid wire with PFA insulation
- Stripped end, lead-wire termination connection
- 91.4 cm (36 in) length

Introduction

Model BB-WTJ-10-36-TT is a versatile thermocouple assembly that easily mounts to a variety of surfaces. It is suitable for surface temperature measurement applications where fixed mounting is possible.

Mounting

Easily mounts to a variety of surfaces.



Ordering Information


Model No.	Description	Lead Length
BB-WTJ-10-36-TT	J-type Thermocouple (ungrounded)	91.4 cm (36 in)

Specifications

Thermocouple Type	J
Wire	20 AWG
Length	900 mm (36 in)
Screw, Nominal Size	#10 (USA) M4.5 (metric)
Insulation	PFA
Temperature Rating	260 °C (500 °F)
Washer Hole Diameter	4.95 mm (0.195 in)
Compliances	RoHS-10, REACH

Mechanical Drawing

Units - mm

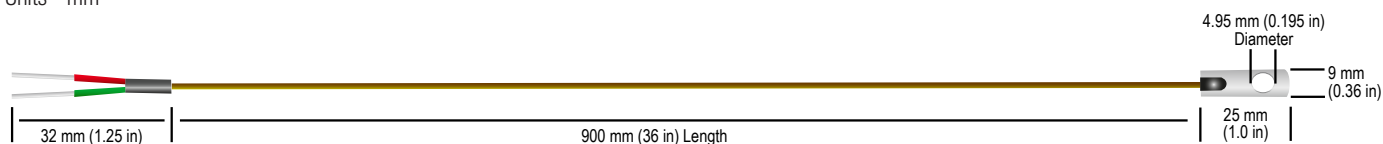

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[BB-WTJ-10-36-TT](#)