


UNOP-1000I UNOP-1000J UNOP-1000K

PCI & Mini-PCI Expansion Card

PCI-104 & Mini-PCle Expansion Card

PCle Expansion Card

NEW

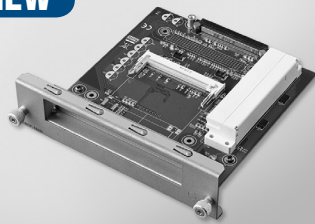

UNOP-1000I



Specifications

General

- **Connector** 120-pin connector for UNO-4673A/PCI, UNO-4683/PCI, ECU-4784/PCI
- **Dimensions** 5.3" x 6.0" (136 x 150 mm)
- **Power Consumption** 5V $\pm$ 5% @ 620mA typical
3.3V $\pm$ 5% @ 75mA typical
- **Certification** CE/FCC

Communications

- **BUS Type** PCI, Mini-PCI (reserved)

Protection

- **Isolation Protection** 2,500 V_{DC}


Environment

- **Operating Temp.** -20 ~ 70°C (-4 ~ 158°F)
- **Operating Humidity** 10 ~ 90% RH non-condensing (refer to IEC 60068-2-3)
- **Storage Humidity** 5 ~ 95% RH non-condensing (refer to IEC 60068-2-3)

Ordering Information

- **UNOP-1000I-BE** PCI & Mini-PCI Expansion card for UNO-4673A, 4683

NEW

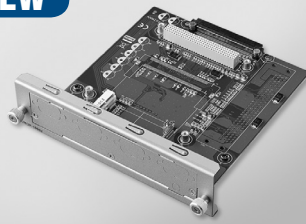

UNOP-1000J



Specifications

General

- **Connector** 120-pin connector for UNO-4673A/PCI, UNO-4683/PCI, ECU-4784/PCI
- **Dimensions** 5.3" x 6.0" (136 x 150 mm)
- **Power Consumption** 5V $\pm$ 5% @ 500mA typical.
3.3V $\pm$ 5% @ 180mA typical.
- **Certification** CE/FCC

Communications

- **BUS Type** PCI-104, Mini-PCle
- **I/O Connectors** 1 x 120-pin box header

Protection

- **Isolation Protection** 2,500 V_{DC}


Environment

- **Operating Temp.** -20 ~ 70°C (-4 ~ 158°F)
- **Operating Humidity** 10 ~ 90% RH non-condensing (refer to IEC 60068-2-3)
- **Storage Humidity** 5 ~ 95% RH non-condensing (refer to IEC 60068-2-3)

Ordering Information

- **UNOP-1000J-BE** PCI-104&Mini-PCle Expansion card of UNO-4673A, 83

NEW

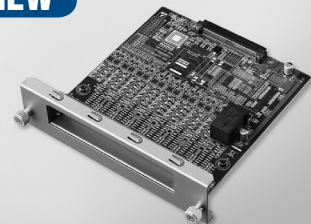

UNOP-1000K



Specifications

General

- **Connector** 120-pin connector for UNO-UNO-4673A/PCle, UNO-4683/PCle, ECU-4784/PCle
- **Dimensions** 5.3" x 6.0" (136 x 150 mm)
- **Power Consumption** 5V $\pm$ 5% @ 400mA typical
3.3V $\pm$ 5% @ 180mA typical.
- **Certification** CE/FCC

Communications

- **BUS Type** PCle x1, Mini-PCle (reserved)

Protection

- **Isolation Protection** 2,500 V_{DC}

Environment

- **Operating Temp.** -20 ~ 70°C (-4 ~ 158°F)
- **Operating Humidity** 10 ~ 90% RH non-condensing (refer to IEC 60068-2-3)
- **Storage Humidity** 5 ~ 95% RH non-condensing (refer to IEC 60068-2-3)

Ordering Information

- **UNOP-1000K-AE** PCle Expansion card for UNO-4673A, 4683

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[UNOP-1000K-AE](#) [UNOP-1000I-BE](#) [UNOP-1000J-BE](#)