

HPC-7000

Server Tower Chassis for EATX/ATX/ MicroATX Motherboard



CE FCC

Features

- Supports EATX/ATX/MicroATX motherboard with dual processors
- Three internal 3.5" HDD bays and one slim ODD drive bay
- Dual front USB 3.0 ports


Specifications

Drive Bay	Slim Optical Drive 3.5"	External	Internal
		1	-
Cooling	Fan	2 (12cm/150CFM)	-
	Air Filter	-	-
Front I/O Interface	USB3.0	2	
Miscellaneous	LED Indicators	Power	
	Rear Panel	Two USB reserved ports	
Environment		Operating	Non-Operating
	Temperature	0 ~ 40 °C (32 ~ 104 °F)	-40 ~ 60 °C (-40 ~ 140 °F)
	Humidity	95% @ 40 °C, non-condensing	95% @ 60 °C, non-condensing
	Vibration (5 ~ 500 Hz)	1 Grms	2 G
	Shock	10 G (with 11 ms duration, half sine wave)	
Physical Characteristics	Dimensions (W x H x D)	267.1 x 458 x 500mm (10.52" x 18.03" x 19.69")	


Front View



Rear View

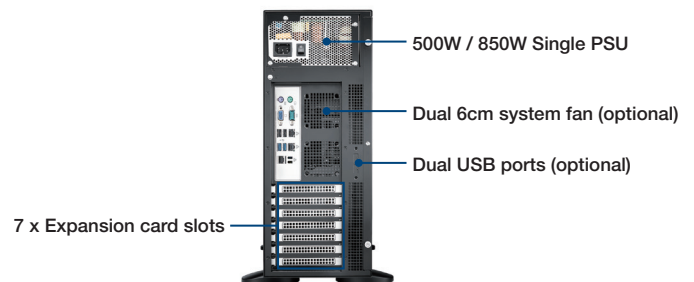


Inside View

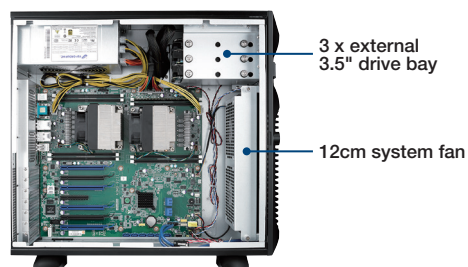

Dimensions

Unit: mm [inch]

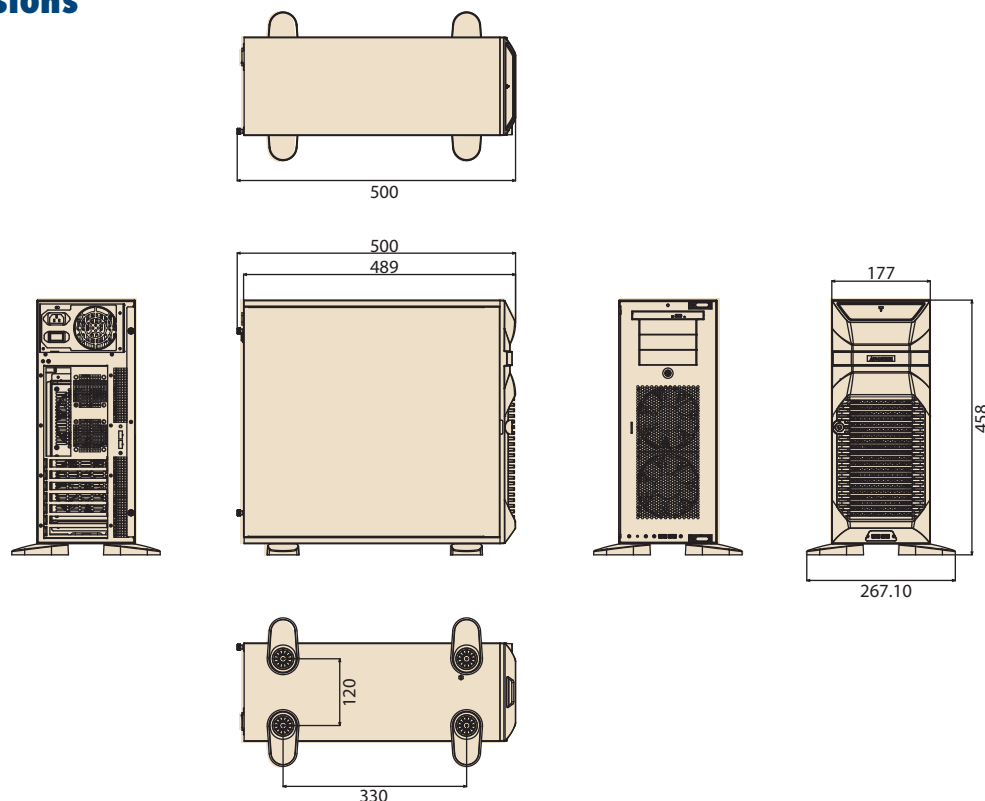

Ordering Information

Part Number	Description
HPC-7000-50ZXE	HPC-7000 Tower chassis w/ 500W SPS
HPC-7000-85ZXE	HPC-7000 Tower chassis w/ 850W SPS

Packing List

Part Number	Description	Quantity
1750008562-01	12cm system fan	2

Note:

1. HPC-7000 does not support AIMB series motherboard

Optional Accessories

Part Number	Description
96CB-SATAPOWER-6P2	SATA power wire 6-pin to big 4-pin (for slim ODD)
989K008734	Convert module for dual 9.6mm(H) 2.5" HDDs in a 3.5" cage
IPC-DT-3120E	Mobile rack for converting a 3.5" drive bay to dual 9.6mm(H) 2.5" HDD trays
1700026948-01	USB 3.0 cable (30cm) for rear panel
1700011592	USB 2.0 cable (50cm) for rear panel
1750006117	6cm system fan (23.6CFM) for rear panel

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[HPC-7000-50ZXE](#) [HPC-7000-85ZXE](#)