

HPC-8212

2U Storage Chassis for ATX/EATX Serverboard with 12 Hot-swap Drive Bays

NEW



Features

- 2U rackmount chassis supports EATX/ATX/uATX motherboard
- 12-bay hot-swappable 3.5"/2.5" SAS 12Gb/s drives or SATA 6Gb/s drives
- 4 x NVMe drives supported via an optional riser card
- Default 7x slots (low profile) rear panel, 3x slots (full height) optional
- Supports 80Plus redundant power supply

CE FCC

Specifications

Drive Bay	3.5"/2.5"	Front	Rear
		12 (Hot Swap)	-
Cooling	Fan	4 (8 cm)	
	Air Filter	-	2 (for R6A1E SKU)
Front I/O Interface	USB	2	
Miscellaneous	LED Indicators	LAN1, LAN2, HDD, Power, and Information LED	
Environment		Operating	Non-Operating
	Temperature	0 ~ 35 °C (32 ~ 95 °F)	-40 ~70 °C (-40 ~158 °F)
	Humidity	10 ~ 95% @ 40 °C, non-condensing	10 ~ 95% @ 60 °C, non-condensing
	Vibration (5 ~ 500 Hz)	0.25 Grms	2 G
Physical Characteristics		Shock	10 G (with 11 ms duration, half sine wave)
	Dimensions (W x H x D)	438 x 88.4 x 620 mm (17.24" x 3.48" x 24.41") / 438 x 88.4 x 540 mm (17.24" x 3.48" x 21.26")	
	Weight	25 kg (without hard drivers)	

Front View




Rear View



Optional full-height rear panel via
98R112SE00E & 98R112AE00E

Dimensions

Unit: mm [inch]

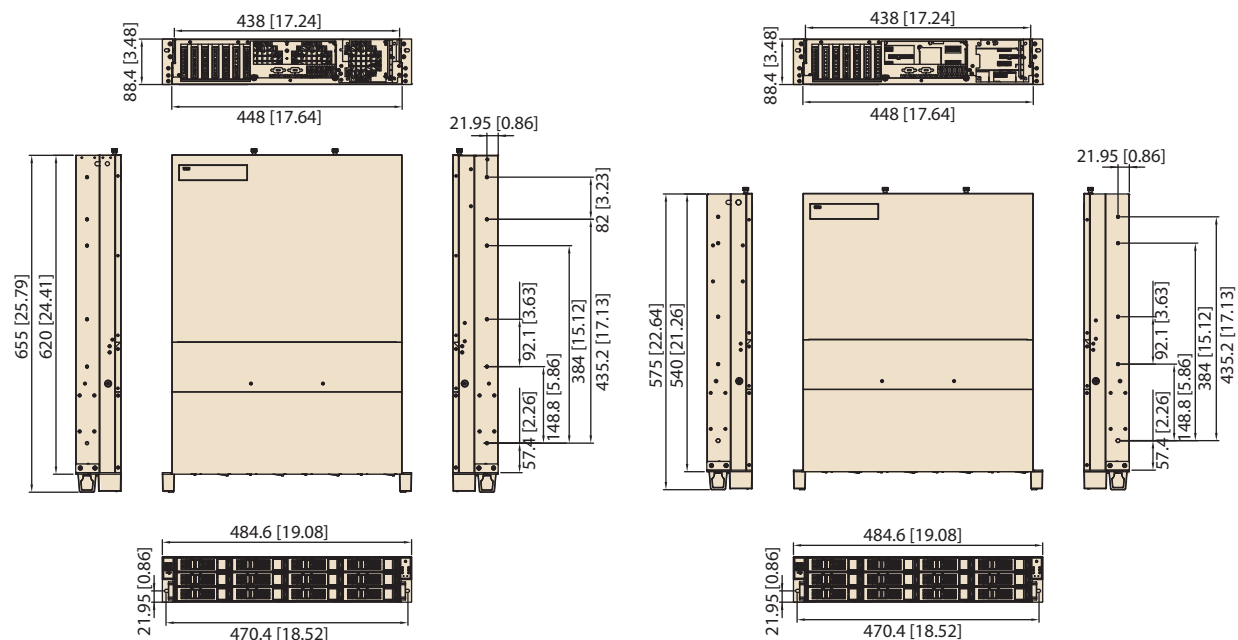

Ordering Information

Part Number	Chassis Depth	Built-in PSU	Front HDD Backplane	Rear HDDs (2 x 2.5")	Default Rail Kit	Motherboard Form-factor	Expansion Slots
HPC-8212SE-R8A1E	620mm	RPSU 800W	SAS12Gb/s	-	26"	EATX, ATX, uATX	x6* Low Profile
HPC-8212SE-R6A1E	620mm	RPSU 650W	SAS12Gb/s	Hot-swap	26"	EATX, ATX, uATX	x6* Low Profile
HPC-8212SA-R5A1E	540mm	RPSU 550W	SAS12Gb/s	-	22"	ATX, uATX	x6* Low Profile

Note: one slot will be occupied by SAS RAID card

Packing List

Part Number	Description	Quantity
9680017208	22" Slide Rail Kit for HPC-8212SA	1
9680017207	26" Slide Rail Kit for HPC-8212SE	1

Optional Accessories

Part Number	Description
98R112SE00E*	Rear Panel kit of Full-Height x3 slots for SE SKU
98R112SA00E*	Rear Panel kit of Full-Height x3 slots for SA SKU
9891821200E	PCIe x16 Riser card for 4-port NVMe drives
1700025064-01	Internal SAS cable (12G) SFF8643 to SFF8643, 60cm
1700025439-01	Internal SAS cable (6G) SFF8643 to SFF8087, 60cm
ASR-1000K-00A1E	JBOD module for SA SKU

Note: an additional ASMB riser card is required.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[HPC-8212SA-R5A1E](#) [HPC-8212SE-R8A1E](#) [HPC-8212SE-R6A1E](#)