

IDS-3212

12" SVGA / XGA Industrial Panel Mount Monitor

NEW



Features

- 12.1" SVGA / XGA LCD panel with LED backlight for 20% power savings, and environmental protection
- 20° C ~ +60° C wide range operating temperature
- 5-wire resistive and P-cap touch screen solution or 3mm tempered smudge resistant protected glass
- Combo touch interface, both RS-232 and USB
- Dual signal interface with VGA & DVI
- Standard integrated frame
- Versatile mounting method for rear mounting and VESA mounting
- Anti-Reflective treatment (optional)
- Ultra high brightness solution of 1200 cd/m² for outdoor applications (optional)



CE FCC

Introduction

The Advantech IDS-3212 Embedded Industrial Panel Mount Monitor series offers flexible options for LCD, touchscreen, signal interface and chassis mounting. The series with standard integrated frame design, supports rear and VESA mounting which brings the benefits of easy installation, and flexibility for different applications.


Specifications

Display	Model	IDS-3212 (XGA)	IDS-3212 (SVGA)	IDS-3212E (SVGA)
	Size	12.1" LED panel	12.1" LED panel	12.1" LED panel
	Resolution	1024 x 768 (XGA)	800 x 600 (SVGA)	800 x 600 (SVGA)
	Viewing Angle	80°/80° (H), 70°/70° (V)	80°/80° (H), 65°/75° (V)	80°/80° (H), 65°/75° (V)
	Brightness	600 (cd/m ²)	450 (cd/m ²)	450 (cd/m ²)
	Color Support	16.2M/262K colors	16.2M/262K colors	16.2M/262K colors
	Contrast Ratio	700:1	700:1	700:1
	Response Time	16 [msec]	35 [msec]	35 [msec]
	Backlight Life (hrs)	50,000 hrs	50,000 hrs	50,000 hrs
Touchscreen	T/S Type	5-Wire Resistive Touchscreen / Projected Capacitive Touchscreen		
	Surface Hardness	3H / 7H		
	Durability	10 million touches / -		
	Transparency	80% / 90% ± 3%		
Environment	Operating Temperature	-20 ~ 60° C (-4 ~ 140° F)	-20 ~ 60° C (-4 ~ 140° F)	0~ 45° C (32 ~ 113° F)
	Storage Temperature	-30 ~ 70° C (-22 ~ 158° F)	-30 ~ 70° C (-22 ~ 158° F)	-20 ~ 60° C (-4 ~ 140° F)
	Humidity	5 ~ 95% @ 40° C, non-condensing		
	Vibration	5-500Hz, 0.026G ² /Hz, 2.16Grms, X, Y, Z 1 hour per axis		
System	I/O	VGA x 1; DVI-D x 1; 12V _{DC} Jack x 1; USB x 1; RS-232 x 1 (USB & RS-232 are reserved for the connection to enable touch usage only)	VGA x1; DVI-D x 1; 12 V _{DC} Jack x 1; USB x 1; RS-232 x 1 (USB & RS-232 are reserved for the connection to enable touch usage only)	VGA x 1; 12 V _{DC} Jack x 1; USB x 1; RS-232 x 1 (USB & RS-232 are reserved for the connection to enable touch usage only)
	OSD	Keys; Menu, Up, Down, Auto Adjust, Monitor Power on/off Menu Function: Brightness, Contrast, Screen Setting, Color Temp, Language OSD settings, VGA/DVI, Recall, Auto Adjust	Keys; Menu, Up, Down, Auto Adjust, Monitor Power on/off Menu Functions: Brightness, Contrast, Screen Setting, Color Temp, Language OSD Settings, VGA/DVI, Recall, Auto Adjust.	Keys; Menu, Up, Down, Auto Adjust, Monitor Power on/off Menu Functions: Brightness, Contrast, Color Adjust, Color Temp, Auto Color, and Language
	Power	36 W power adapter, with AC 100 ~ 240 V input and DC +12V @ 3 A output		
	EMC Compliance	CE/FCC/CCC		


Dimensions

Unit: mm


IDS-3212 (XGA) Series

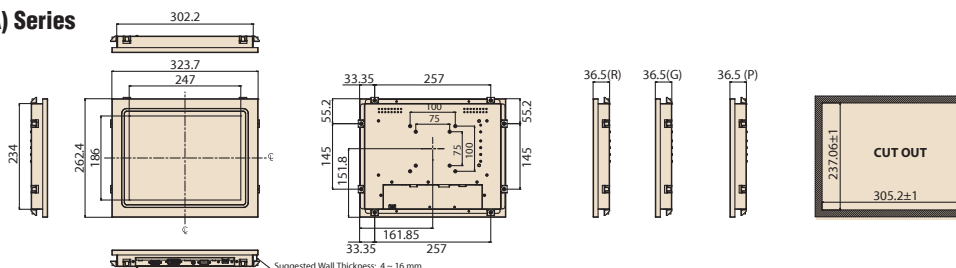

IDS-3212 (SVGA) Series

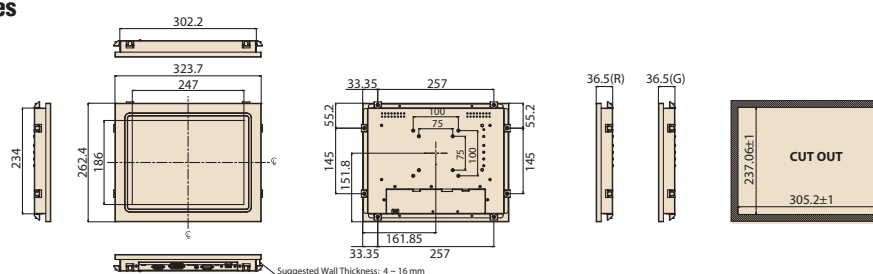

IDS-3212E (SVGA) Series

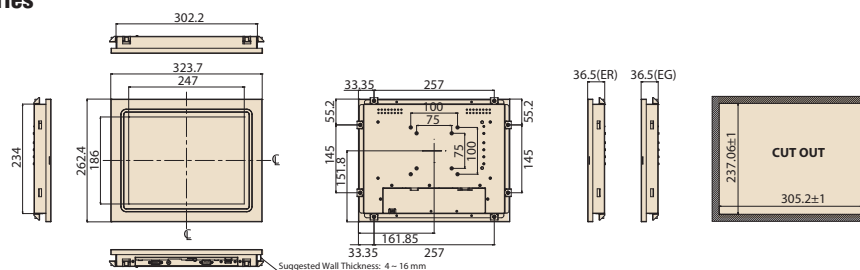

Packing List

Part Number	Description
1700002215	1 x M Cable USB-A(M)/USB-A(M) 180CM
1700021332-01	1 x VGA cable 15P(M) 180 cm
1962055040	4 x Clamper
1935042520	4 x Screw of clamper M4_25L
1992610005	1 x Cable clamp
1933030500	1 x Screw of cable clamp
1992602010	1 x Cable tie

* USB Cable is only included with IDS-3212R and IDS-3212ER series. Note: Package contents are subject to change without prior notice


Ordering Information

Model Name	Description
IDS-3212G-60XGA1E	12.1" XGA 600 cd/m ² LED Panel Mount Monitor
IDS-3212R-60XGA1E	12.1" XGA 600 cd/m ² LED Panel Mount Monitor with Res. Touch
IDS-3212G-45SVA1E	12.1" SVGA 450 cd/m ² LED Panel Mount Monitor
IDS-3212R-45SVA1E	12.1" SVGA 450 cd/m ² LED Panel Mount Monitor with Res. Touch
IDS-3212EG-45SVA1E	12.1" SVGA 450 cd/m ² LED Panel Mount Monitor
IDS-3212ER-45SVA1E	12.1" SVGA 450 cd/m ² LED Panel Mount Monitor with Res. Touch
IDS-3212P-60XGA1	12.1" XGA 600 cd/m ² LED Panel Mount Monitor with P-Cap Touch

Optional Items


Part Number	Description
1700001524	3-Pin Power Cord (USA)
170203183C	3-Pin Power Cord (EU)
1700008921	3-Pin Power Cord with PSE (Japan)
96PSA-A36W12R1	Adaptor AC100-240V 36W +12V/3A
1700000243-11	M cable DVI 19P(M)/DVI 19P(M) 191cm
1700091800	CABLE 9P/9P 1.8M M/F (T/S RS-232 Cable)

IO view

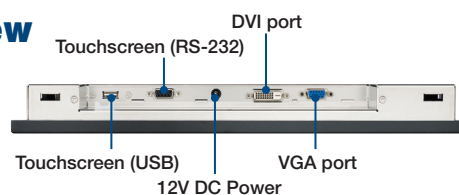

Rear View

- VESA Mounting**
- 75 x 75mm
 - 100 x 100mm
- I/O Port**
- 12V DC
 - VGA
 - DVI
 - RS-232
 - USB

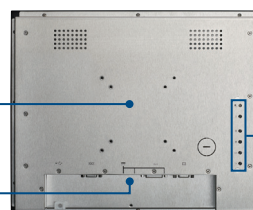

- OSD Key**
- Power
 - Menu
 - Auto
 - Adjust +
 - Adjust -

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[IDS-3212R-45SVA1E](#) [IDS-3212ER-45SVA1E](#) [IDS-3212R-60XGA1E](#) [IDS-3212G-45SVA1E](#) [IDS-3212EG-45SVA1E](#)
[IDS-3212G-60XGA1E](#)