

# MIOe-PWR1

## 12-24V DC to DC Power Module


### MI/O-Chassis compliant

# MIOe-PWR2

## 9-36V DC to DC Power Module


### MI/O-Chassis compliant

NEW

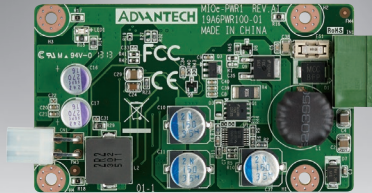

UL CB CE FCC

NEW

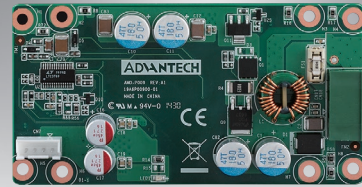

UL CB CE FCC

### Specifications

|                              |                       |  |
|------------------------------|-----------------------|--|
| General                      | Input Voltage         | 12 to 24 V <sub>DC</sub> ±5%               |
|                              | Output Voltage        | 12V ±10%                                   |
|                              | Output Current        | Max. 5A                                    |
|                              | Protection            | OVP, OCP, Anti-reverse                     |
|                              | Connector type        | Input: Phoenix 2pin<br>Output: ATX 2x2pin  |
| Mechanical and Environmental | Dimensions (L x W)    | 90 x 53 mm (3.5" x 2.1")                   |
|                              | Operating Temperature | 0 ~ 60° C (32 ~ 140° F)                    |
|                              | Weight                | 0.084 kg (0.185 lb)                        |
|                              | Operating Humidity    | 0% ~ 90% relative humidity, non-condensing |

### Ordering Information

| P/N              | Description                            |
|------------------|--|
| MIOe-PWR1-00A1E  | 12-24V DC to DC power module           |
| MIOe-PWR1Z-00A1E | 12-24V DC power module<br>-20 ~ 80 ° C |

### Accessories

| Part No.      | Description                         |
|---------------|-------------------------------------|
| 1700021072-01 | Power cable 2*2P-4.2/2*2P-4.2, 10cm |

### Specifications

|                              |                       |  |
|------------------------------|-----------------------|--|
| General                      | Input Voltage         | 9 to 36 V <sub>DC</sub>                          |
|                              | Output Voltage        | 12V ±10%   |
|                              | Output Current        | Max. 5A  |
|                              | Protection            | OVP, OCP, Anti-reverse                           |
|                              | Connector type        | Input: Phoenix 2pin<br>Output: 4pin 2.54mm Wafer |
| Mechanical and Environmental | Dimensions (L x W)    | 102 x 53 mm (4" x 2.1")                          |
|                              | Operating Temperature | 0 ~ 60° C (32 ~ 140° F)                          |
|                              | Weight                | 0.115 kg (0.253 lb)                              |
|                              | Operating Humidity    | 10~95% R.H. @ 40C, 95% R.H. non-condensing       |

### Ordering Information

| P/N             | Description                 |
|-----------------|-----------------------------|
| MIOe-PWR2-00A1E | 9-36V DC to DC power module |

### Accessories

| Part No.      | Description                      |
|---------------|----------------------------------|
| 1700023499-01 | Power cable 2*2P-4.2/1*4-2.5 5cm |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[MIOE-PWR2-00A1E](#)