


PCE-7131

LGA1151 8th Generation Intel® Xeon® E/ Core™ i7/i5/i3/Pentium® LGA1151 System Host Board with DDR4, SATA 3.0, USB 3.1, M.2, Dual GbE, and Triple Displays

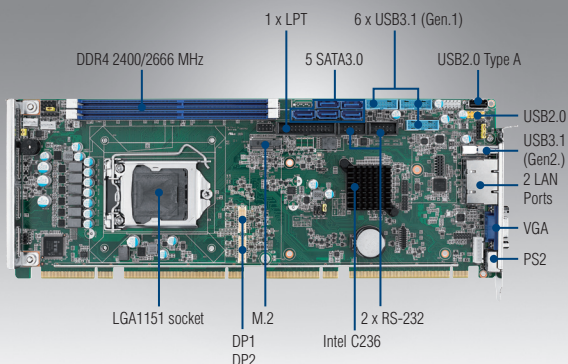

Features

- Intel® Xeon® E Family/Core™ i7/i5/i3 LGA1151 processor with C246 chipset
- Up to 32 GB of dual-channel (non-ECC) DDR4 2400/2666 MHz
- PCIe 3.0, M.2, USB 3.1, SATA 3.0, and SW Raid 0, 1, 5, 10
- Supports VGA and 2 x DVI-D/DP display (with optional cable)
- Supports out-of-band remote management with AMT
- Supports Advantech's LPC modules, SUSIAccess, and embedded software APIs

Note: Intel 8th generation processors only support Windows 10 (64-bit)


Quiet

Specifications

CE FCC

Processor System	CPU	i7-8700	i7-8700T	i5-8500	i5-8500T	i3-8100	i3-8100T	G5400	G5400T	G4900	G4900T	Xeon E Family
	Base Frequency	3.2 GHz	2.4 GHz	3.0 GHz	2.1 GHz	3.6 GHz	3.1 GHz	3.7 GHz	3.1 GHz	3.1 GHz	2.9 GHz	3.80GHz
	L3 Cache	12 MB	12 MB	9 MB	9 MB	6 MB	6 MB	4 MB	4 MB	2 MB	2 MB	12MB
	SKU/Chipset	Intel® C246										
	BIOS	AMI® SPI Flash 256 Mbit										
Bus	PCI-Express	1 x PCIe x16/2 x PCIe x8 and 1 x PCIe x4 to backplane										
	PCI	4 x PCI master to backplane, 32-bit, 33 MHz										
Memory	Technology	Dual-channel (non-ECC) U-DIMM DDR4 2400/2666 MHz (supports x8 DDR4 1024 M) (Note: Intel ECC-supported processor must be selected to enable ECC function)										
	Max. Capacity	32 GB (16 GB per DIMM)										
	Socket	2 x DDR4 288-pin DIMM										
Graphics	Controller	Chipset integrated with Intel® HD Graphics										
	VRAM	Shared system memory is subject to OS										
	VGA	Supports resolutions of up to 1920 x 1200 pixel @ 60 MHz										
	DVI-D	Supports resolutions of up to 1920 x 1200 pixel @ 60 MHz										
	Display Port	Supports resolutions of up to 1920 x 1080 pixel @ 60 Hz										
	Triple Display	VGA+DP/DVI-D+DP/DVI-D										
Ethernet	Interface	10/100/1000 Mbps										
	Controller	LAN 1: Intel® I219-LM LAN 2: Intel® I210-AT										
	Connector with LED	2 x RJ45										
Rear I/O	USB 3.1 Gen2	1										
	Ethernet	2										
	VGA	1										
	PS/2	1 (PS/2 Y cable supports 1 x keyboard and 1 x mouse)										
Internal Connector	USB	7 x USB 2.0 (pin header*2 + USB Type A*1 + 4 on backplane) 4 x USB 3.0 (pin header)										
	SATA (SW Raid 0,1,5,10)	5										
	M.2 (2280 Type M)	1 (supports SATA 3.0)										
	DP/DVI-D	2 (Pin header)										
	COM	2										
	Parallel	1										
	IrDA	1										
	GPIO	8bit										
Watchdog Timer	Output	System reset										
	Interval	Programmable 1-255 sec										
Miscellaneous	Audio	Intel® High Definition audio interface (requires audio extension module PCA-AUDIO-HDB1E)										
Power Requirement	Test Environment	i7-8700, 3.2 GHz, with 2 x 8-GB DDR4 2400										
	Voltage	+12V							+3.3V			
	Current	4.30A							0.69A			
Environment	Operating								Non-Operating			
	Temperature	0 ~ 60 °C (dependent on CPU and cooler solution)							-40 ~ 85 °C			
	Humidity	40 °C @ 85% relative humidity (non-condensing)							60 °C @ 95% relative humidity (non-condensing)			
Physical	Dimensions (L x H)	338 x 122 mm (13.3" x 4.8")										

Block Diagram

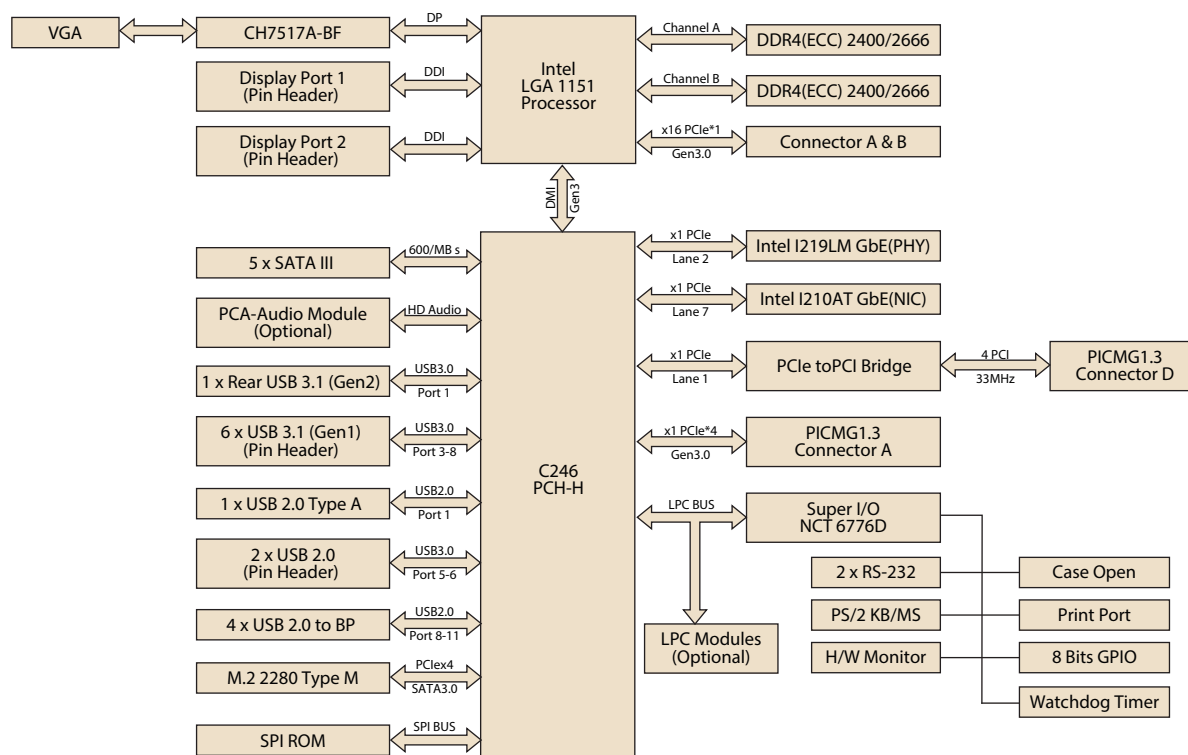

Ordering Information

Part Number	PCH	Memory	Backplane	LAN	VGA	DP/DVI-D	COM	SATA III	M.2	USB 2.0	USB 3.1 (Gen1)	USB3.1 (Gen2)	S/W Raid	AMT
PCE-7131G2-00A1	C246	ECC/Non-ECC	PCE-5BXX PCE-7BXX	2	Yes	2*	2	5	1	7	6	1	Yes	Yes

Note: DP/DVI-D cable is optional

Packing List

Part Number	Description	Quantity
1700003194	Serial ATA HDD data cable	x2
1700022749-11	Serial ATA HDD power cable	x1
1701260305	COM + printer ports cable kit	x1
1700060202	Keyboard and mouse Y-cable	x1
1700022204	2-port USB cable kit	x1
9689000068	Jumper package	x1
2190000902	Warranty card	x1
2001512910	Startup manual	x1
2061512900	Utility CD	x1

Optional Accessories

Part Number	Description
1960052651N021	2U CPU cooler (PWM fan)
1960049408N001	CPU cooler for 1U chassis
PCA-AUDIO-HDB1E	Audio module
PCA-TPM-00A1E	TPM 1.2 module
PCA-COM232-00A1E	4-port RS-232 LPC module
PCA-COM485-00A1E	4-port RS-422/485 LPC module
1700020277-01	2-port USB 3.0 cable w/ BKT (30 cm)
1700021831-01	DP to DVI-D cable w/ BKT
PCE-DP10-00A1E	DP to DP cable w/ BKT
PCA-TPM-00B1E	TPM 2.0 module

I/O View



PCE-7131G2-00A1E

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[PCE-7131G2-00A1](#)