

PPC-3151W

15.6" Fanless Widescreen Panel PC with Intel® Core™ i5-7300U Processor



Features

- 15.6" true-flat Full HD LCD panel with projected capacitive touchscreen, anti-glare coating
- Intel® Core™ i5-7300U(default); i7-7600U/i3-7100U(optional) processor with fanless system design
- Supports PCIe x4 or PCI expansion
- 1 x isolated RS-422/485 with auto flow
- Wide input power range (9 ~ 32 V_{DC})
- Dual Gigabit Ethernet with IEEE1588 support
- 3 x Independent displays
- 1 x M.2 bay (2242) for storage only
- 1 x TPM 2.0 internal support (optional)
- Supports VESA 100 mounting interface



Introduction


PPC-3151W is a new generation industrial interactive panel PC with a 15.6" TFT full HD LCD 1920 x 1080 resolution, which features a flat, sleek design to greatly reduce maintenance effort. Pre-installed Intel® Core™ i processor and designed fanless architecture, PPC-3151W provide high performance and reliable system for factory automation or variety of industrial applications. Furthermore, with the provision of multiple I/O, dual Intel® Gigabit ethernet, PCI/PCIe expansion, PPC-3151W ensures easy integration and connectivity.

Specifications

System	CPU	Intel® Core™ i5-7300U dual core (default); i7-7600U/i3-7100U (optional)
	Frequency	2.6 GHz, up to 3.5 GHz with turbo
	L2 Cache	3 MB
	Memory	1 x SODIMM DDR4 1866/2133 MHz, (max. 16 GB)
	Storage	1 x 2.5" SATA bay 1 x M.2 bay (size: 22 x 42 mm, socket 2 B key, for storage only)
	Network (LAN)	2 x 10/100/1000 Mbps Ethernet (Intel® I211-AT; Intel® I219LM)
	I/O	2 x RS-232, 1 x RS-422/485 with 1K V _{DC} isolation Either 2 x RS-232 or 1 x RS-232 + 1 x GPIO(TTL, 8 pin programmable) on right side (optional module) 4 x USB 3.0 1 x Line-out, 1 x Mic-in 1 x DB15 VGA 1 x Display Port (1.2) 1 x TPM 2.0 internal(optional)
	Expansion	1 x Mini PCIe 1 x PCIe x 4 (default); 1 x PCI (in the accessory box)
	Watchdog Timer	255 timer levels, set up by software
	Speaker	2 x 1W
Physical Characteristics	Dimensions	419.7 x 269 x 59 mm (16.5 x 10.6 x 2.3 in)
	Weight	5.4kg (11.9 lb)
OS Support	OS Support	Microsoft® Windows 10 (64-bit), Win 10 LTSC, Linux
Power Consumption	Input Voltage	9 ~ 32 V _{DC}
	Power Consumption	i5-7300U 65W(Burn-in test 8.1 in Windows 10 64bit
LCD	Display Type	15.6" TFT LCD (LED backlight)
	Max. Resolution	1920 x 1080
	Viewing Angle	85 (Left), 85 (Right), 85(Up), 85(Down)
	Luminance (cd/m ²)	450
	Contrast Ratio	800
	Backlight Lifetime	50,000 hr (min.)
Touchscreen	Touch Type	Multi-touch projected capacitive
	Light Transmission	88 % ± 2 %
	Controller	USB interface
Environment	Operating Temperature	0 ~ 50 °C (32 ~ 122 °F) with SSD; 0 ~ 40 °C (32 ~ 104 ° F) with HDD
	Storage Temperature	-20 ~ 60 °C (-4 ~ 140 °F)
	Relative Humidity	10 ~ 95% @ 40 °C (Non-Condensing)
	Shock	Operating 10 G Peak Acceleration (11 ms Duration), Follows IEC 60068-2-27
	Vibration	Operating Random Vibration Test 5 ~ 500Hz, 1Grms @with HDD; 2Grms @with SSD, Follows IEC 60068-2-64
	EMC	CE, FCC Class B, BSMI
	Safety	CB, UL, CCC, BSMI
	Front Panel Protection	IP65 compliant

Dimensions

Unit: mm

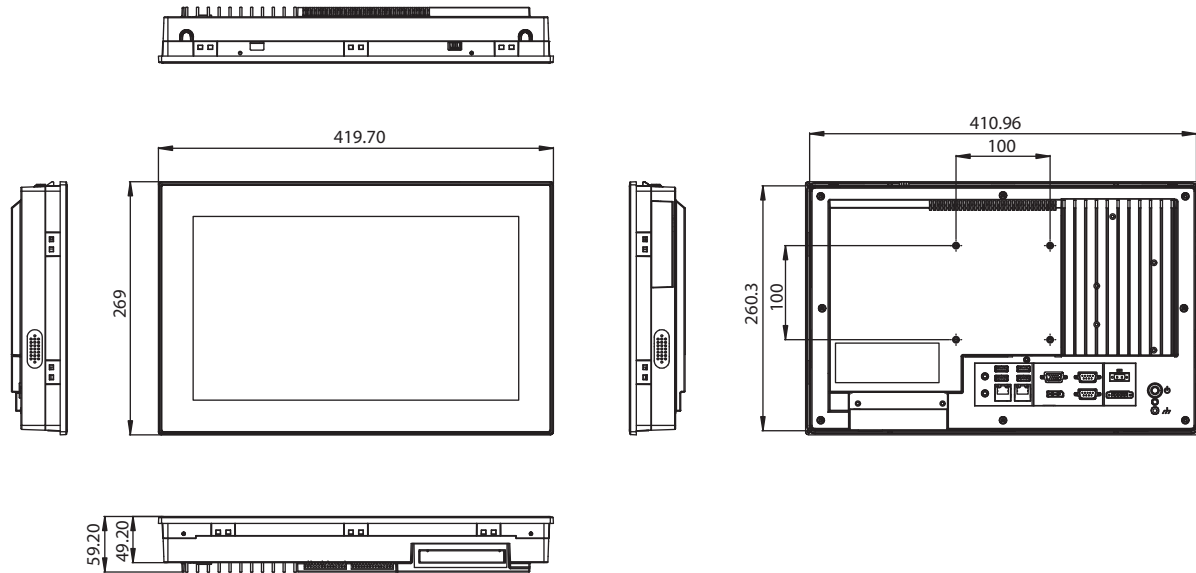


Cut-Out Dimension: 413.00 x 262.00 mm

Ordering Information

Part Number	Description
PPC-3151W-P75A	15.6" Wide screen PPC with PCT Multi-touch, Intel Core i5-7300U
PPC-3151W-P75AU	15.6" Wide screen PPC with PCT Multi-touch, Intel Core i5-7300U, for U.S. only
96PSA-A90W190T-3	A/D 100-240V 90W 19V C6 TERMINAL 2 PIN 62368
1700001524	POWER Cord 3P UL 10A 125V 180cm
170203183C	POWER Code 3P Europe (WS-010+083)183cm
1700008921	POWER CORD 3P/3P POWER SUPPLY 1.8M PSE
96CB-POWER-B-1.8MB	Power code 3P CCC(China) 1.8M
PPC-174T-WL-MTE	Wall mount kit for PPC series
PPC-STAND-A1E	Stand for PPC series
PPC-ARM-A03	ARM VESA Standard (A-CLEVER) for PPC series
PPC-WLAN-C1E	M.2 Wi-Fi Module with Antenna cable support 2T2R
98R3P321100	Optional module on right side: Either 2 x RS-232 or 1 x RS-232 + 1 x GPIO(TTL, 8 pin programmable)
98R3P321110	TPM 2.0 module

I/O View

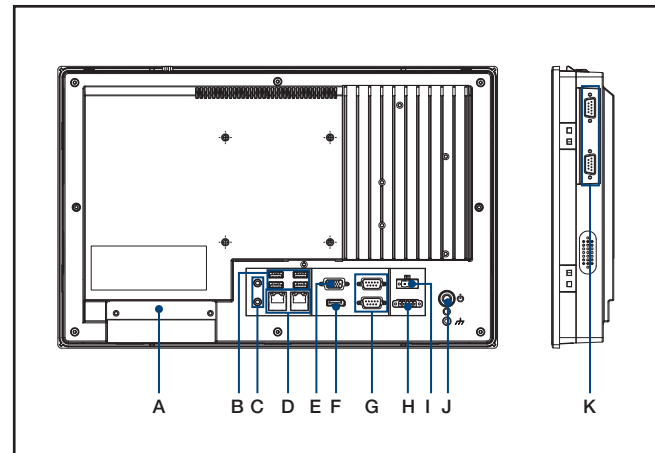

- A. 1 x Expansion slot (PCI or PCIe x1)
- B. 4 x USB3.0
- C. 1 x Mic-In/Line-Out
- D. 2 x Intel Gigabit Ethernet
- E. 1 x VGA
- F. 1 x DisplayPort
- G. 2 x RS-232
- H. 1 x Isolated RS-422/485
- I. 1 x DC inlet and AT/ATX switch
- J. 1 x Power button
- K. 2 x RS-232 (on right side optional)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[PPC-3151W-P75AU](#)