

Low Voltage DC Power Cord

Locking Female Barrel Connector, Stripped/Tinned Leads
Model PSPT-LB



- FEATURES**
- Standard DC Power Plug
 - Molded Strain Relief
 - 2.5 x 5.5mm Locking Barrel Connector
 - Stripped and Tinned Leads
 - 6.5mm Locking Thumb Screw
 - 1m (39.4in) Length

Model PSPT-LB is a power cable with a 2.5x5.5mm threaded locking barrel plug on one end and stripped and tinned leads on the other - for use with industrial power supplies.

ORDERING INFORMATION


MODEL NUMBER	DESCRIPTION
PSPT-LB	Low-voltage DC Power Cord, Barrel, Stripped/Tinned Leads, 1 m

SPECIFICATIONS

Cable Type/Size	SPT-1 cord, 18AWG x 2, stranded wire, 300V, 75 °C rated, PVC jacket	
Cable Jacket Color	Black	
Polarity	Stripe conductor connected to inner of barrel(+)	
Overall Length	1000 +100, -0 mm	
Cable Outer Diameter	2.7 x 5.4 +/- 0.1 mm	
End "A" Termination (P1)	Locking female barrel, 5.5 x 2.5mm, with 6.5mm locking thumb screw	
End "B" Termination	Lead wires, stripped and tinned	
Strain Relief	SR2 type for GT-21097 enclosure	
Compliance	RoHS	
COLOR	SPLIT (MM)	STRIP & TIN (MM)
Ribbed	74	9
Smooth	74	9

MECHANICAL DRAWING

Units = mm

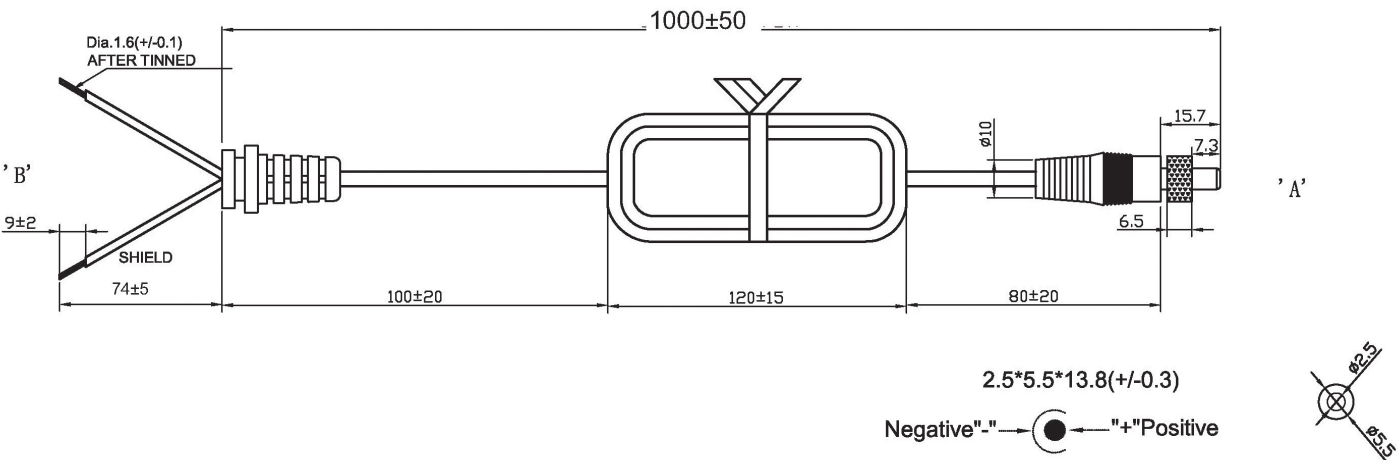

All product specifications are subject to change without notice.
PSPT-LB_0218ds

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[BB-PSPT-LB](#)