

PWR-242

PWR-243

DIN-rail Power Supply

Panel Mount Power Supply



PWR-242



Specifications

Input

- Input Current 1.2 A max.
- Inrush Current (cold) 20 A/110 V_{AC}
40 A/220 V_{AC}
- Input Frequency 47 ~ 63 Hz
- Input Voltage 90 ~ 264 V_{AC} wide input range
- Short Protection

Output

- Output Current 2.1 A max.
- Output Voltage +24 V_{DC} ±10%
- Overload Protection


General

- Certifications CE, FCC, UL
- Connectors Screw-terminal
- Dimensions (L x W x H) 181 x 113 x 60 mm (7.01" x 4.43" x 2.35")
- Enclosure Sheet metal
- MTBF 85,000 hrs
- Operating Temperature 0 ~ 50° C (32 ~ 122° F)

Ordering Information

- PWR-242 DIN-rail Power Supply

Dimensions

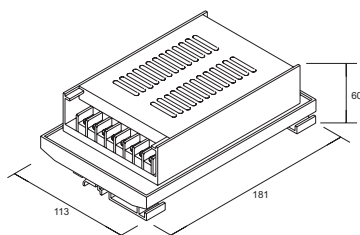

Unit: mm



PWR-243



Specifications

Input

- Input Current 1.4 A max.
- Inrush Current (cold) 20 A/110 V_{AC}
40 A/220 V_{AC}
- Input Frequency 47 ~ 63 Hz
- Input Voltage 85 ~ 132 V_{AC} or 170 ~ 264 V_{AC} (switchable)
- Short Protection

Output

- Output Current 3 A max.
- Output Voltage +24 V_{DC} ±10%
- Overload Protection


General

- Certifications CE, FCC, UL
- Connectors Screw-terminal
- Dimensions (L x W x H) 128 x 97 x 40 mm (5" x 3.8" x 1.6")
- Enclosure Sheet metal
- MTBF 78,000 hrs
- Operating Temperature 0 ~ 50° C (32 ~ 122° F)

Ordering Information

- PWR-243 Panel Mount Power Supply

Dimensions

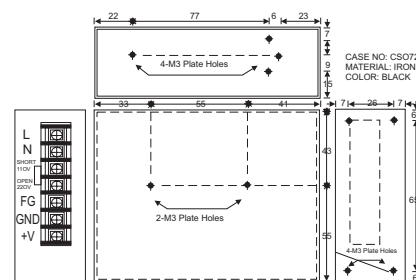

Unit: mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[PWR-242-AE](#)