


SQR-RD4N Series

RDIMM DDR4 Server memory

NEW

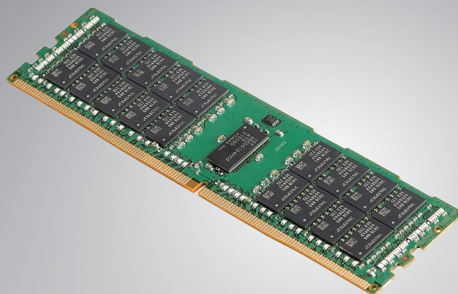

Features

- JEDEC standard 1.2V (1.26V~1.14V) power supply
- JEDEC standard 288-pin RDIMM
- Original Samsung Chip
- ECC function with Register
- 30u" Gold Finger
- Capacity upto 32GB

Specifications

Category	DDR4
Speed	2133/2400/2666 Mbps
Voltage	1.2 V +/- 0.06 V
Pins/DIMM	288-pin RDIMM
Gold Plating on PCB Gold Fingers	30u"
Dimensions (mm)	133.35 x 31.25

Ordering Information

Part No.	Product Description
SQR-RD4N-8G2K6SRBB	288pin RDIMM D4 2666 8GB, (0-85), ECC Register SAM
SQR-RD4N16G2K6SRAB	288pin RDIMM D4 2666 16GB, (0-85), ECC Register SAM
SQR-RD4N32G2K6SRAB	288pin RDIMM D4 2666 32GB, (0-85), ECC Register SAM

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[SQR-RD4N16G2K4SZBB](#) [SQR-RD4N8G2K4SZBBB](#)