


SQR-SD4M

SODIMM DDR4 WIDE TEMP (-20~85°C)

SQR-SD4I

SODIMM DDR4 WIDE TEMP (-40~85°C)

NEW

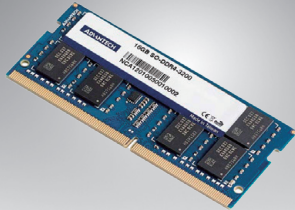

Features

- Data Transfer Rate: 3200 MT/s
- Original Samsung IC chip
- Thermal Sensor attached
- DRAM Software Temperature Monitoring
- Fixed BOM & Lifetime warranty


Specifications

DDR Type	DDR4
Pin / DIMM	260pin SODIMM
Data Transfer Rate	2666;3200 MT/s
Capacity	4/8/16/32GB
Golden Finger	30u"
Power Supply	1.2V
Operating Temperature	-20 ~ 85 °C

Ordering Information

PN	Description
SQR-SD4M4G2K6SNEFB	SODIMM DDR4 2666 4GB 512Gx8, -20 ~ 85 °C
SQR-SD4M8G2K6SNBCB	SODIMM DDR4 2666 8GB 1Gx8, -20 ~ 85 °C
SQR-SD4M16G2K6SNCB	SODIMM DDR4 2666 16GB 1Gx8, -20 ~ 85 °C
SQR-SD4M4G3K2SNEFB	SODIMM DDR4 3200 4GB 512Gx8, -20 ~ 85 °C
SQR-SD4M8G3K2SNBCB	SODIMM DDR4 3200 8GB 1Gx8, -20 ~ 85 °C
SQR-SD4M16G3K2SNCB	SODIMM DDR4 3200 16GB 1Gx8, -20 ~ 85 °C
SQR-SD4M32G3K2SNAB	SODIMM DDR4 3200 32GB 2Gx8, -20 ~ 85 °C

NEW

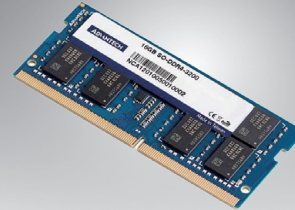

Features

- Data Transfer Rate: 3200 MT/s
- Original Samsung IC chip
- Thermal Sensor attached
- DRAM Software Temperature Monitoring
- Fixed BOM & Lifetime warranty

Specifications

DDR Type	DDR4
Pin / DIMM	260pin SODIMM
Data Transfer Rate	2666;3200 MT/s
Capacity	4/8/16/32GB
Golden Finger	30u"
Power Supply	1.2V
Operating Temperature	-40 ~ 85 °C

Ordering Information

PN	Description
SQR-SD4I4G2K6SNEFB	SODIMM DDR4 2666 4GB 512x8, -40 ~ 85 °C
SQR-SD4I8G2K6SNBCB	SODIMM DDR4 2666 8GB 1Gx8, -40 ~ 85 °C
SQR-SD4I16G2K6SNCB	SODIMM DDR4 2666 16GB 1Gx8, -40 ~ 85 °C
SQR-SD4I4G3K2SNEFB	SODIMM DDR4 3200 4GB 512x8, -40 ~ 85 °C
SQR-SD4I8G3K2SNBCB	SODIMM DDR4 3200 8GB 1Gx8, -40 ~ 85 °C
SQR-SD4I16G3K2SNCB	SODIMM DDR4 3200 16GB 1Gx8, -40 ~ 85 °C
SQR-SD4I32G3K2SNAB	SODIMM DDR4 3200 32GB 2Gx8, -40 ~ 85 °C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Advantech:

[SQR-SD4I16G2K4SNBB](#) [SQR-SD4N-16G2K4HBC](#) [SQR-SD4N-4G2K1HEC](#) [SQR-SD4N-8G2K4HBC](#) [SQR-SD4N16G2K4SNBB](#) [SQR-SD4N4G2K4SNEEB](#) [SQR-SD4N8G2K4SNBBB](#) [SQR-SD4M-16G2K1SNB](#) [SQR-SD4M-8G2K1SNB](#) [SQR-SD4I-16G2K1SNB](#)