


SQR-SD4N

SODIMM DDR4 2666

SQR-UD4N

UDIMM DDR4 2666

NEW

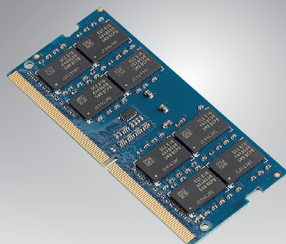

Features

- JEDEC Standard 260-pin Small Outline Dual In-Line Memory Module
- Data Transfer Rate: 2666 MT/s
- Anti sulfuration DRAM module
- Original Samsung IC chip
- Thermal Sensor


Specifications

DDR Type	DDR4
Pin / DIMM	260pin SODIMM
Data Transfer Rate	2666 MT/s
Golden Finger	30u"
Capacity	4GB ~ 32GB
Power Supply	1.2V (1.26V~1.14V)
Operating Temperature	0 ~ 85 °C
Dimensions (mm)	69.6 x 30 ± 0.13

Ordering Information

PN	Description
SQR-SD4N4G2K6SNEFB	260pin SODIMM DDR4 2666 4GB 1.2v 512Mx8 (0 ~ 85 °C) SAM
SQR-SD4N8G2K6SNBCB	260pin SODIMM DDR4 2666 8GB 1.2v 1Gx8 (0 ~ 85 °C) SAM
SQR-SD4N16G2K6SNCB	260pin SODIMM DDR4 2666 16GB 1.2v 1Gx8 (0 ~ 85 °C) SAM
SQR-SD4N32G2K6SNME	260pin SODIMM DDR4 2666 32GB 1.2v 2Gx8 (0 ~ 85 °C) SAM

NEW

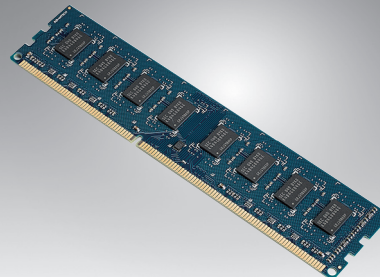

Features

- JEDEC Standard 288-pin Dual In-Line Memory Module
- Data Transfer Rate: 2666 MT/s
- Anti sulfuration DRAM module
- Original Samsung IC chip
- Thermal Sensor

Specifications

DDR Type	DDR4
Pin / DIMM	288pin UDIMM
Data Transfer Rate	2666 MT/s
Golden Finger	30u"
Capacity	4GB ~ 32GB
Power Supply	1.2V (1.26V~1.14V)
Operating Temperature	0 ~ 85 °C
Dimensions (mm)	133.35 x 31.25

Ordering Information

PN	Description
SQR-UD4N4G2K6SNEFB	288pin UDIMM DDR4 2666 4GB 1.2v 512Mx8 (0 ~ 85 °C) SAM
SQR-UD4N8G2K6SNEFB	288pin UDIMM DDR4 2666 8GB 1.2v 512Mx8 (0 ~ 85 °C) SAM
SQR-UD4N8G2K6SNBCB	288pin UDIMM DDR4 2666 8GB 1.2v 1Gx8 (0 ~ 85 °C) SAM
SQR-UD4N16G2K6SNCB	288pin UDIMM DDR4 2666 16GB 1.2v 1Gx8 (0 ~ 85 °C) SAM
SQR-UD4N32G2K6SNME	288pin UDIMM DDR4 2666 32GB 1.2v 2Gx8 (0 ~ 85 °C) SAM

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[SQR-SD4N8G3K2SNBCB](#) [SQR-SD4N4G2K6SNEFB](#)