


UPOS-M07G

7" 2nd display for UPOS-211 Series

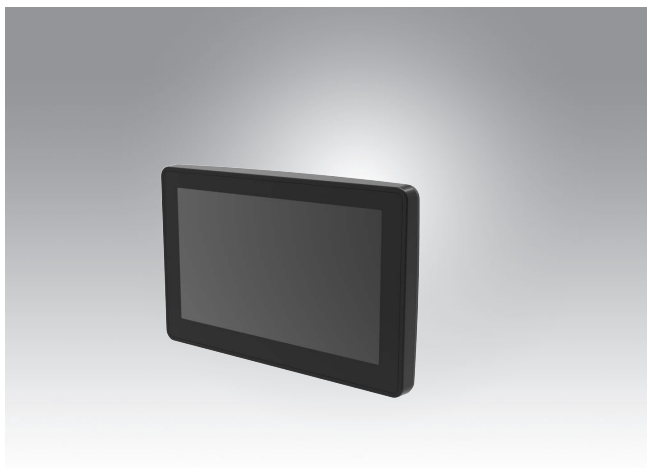

Specifications

Resolution	7"LCD Monitor (LED Backlight)/ 800 x 480
Brightness	350 cd/m2
Ratio	16:9
Signal Input	USB
Color Option	Black,White
Power	DC 5V
OS Support	Windows 7/8/10
Dimensions	189 x121 x 52 mm
Operating Temperature	0 ~ 40° C

Packing List

Description	Quantity
7" display Unit	1
Screw	2
Installation Guide	1

Ordering Information

P/N	Description
UPOS-M07G-BST00	10.1" 2nd display,PCAP, rear mount for UPOS-211,black
UPOS-M07G-WST00	10.1" 2nd display,PCAP, rear mount for UPOS-211, White

UPOS-M10G

10" 2nd display for UPOS-211 Series



Specifications

Resolution	10.1" LCD Monitor (LED Backlight)/ 1024 x 600
Brightness	200 cd/m2
Ratio	16 : 9
Signal Input	VGA
Color Option	Black,White
Power	DC12V
OS Support	Windows 7/8/10, Linux
Dimensions	269 x171 x 66 mm
Operating Temperature	0 ~ 40° C

Packing List

Description	Quantity
10.1" display Unit	1
Screw	2
User manual	1

Ordering Information

P/N	Description
UPOS-M10G-BST00	10.1" 2nd display,PCAP, rear mount for UPOS-211,black
UPOS-M10G-WST00	10.1" 2nd display,PCAP, rear mount for UPOS-211, White

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[UPOS-M10G-BST00](#) [UPOS-M07G-BST00](#)