


UPOS-P01

VFD, rear mount for UPOS-211

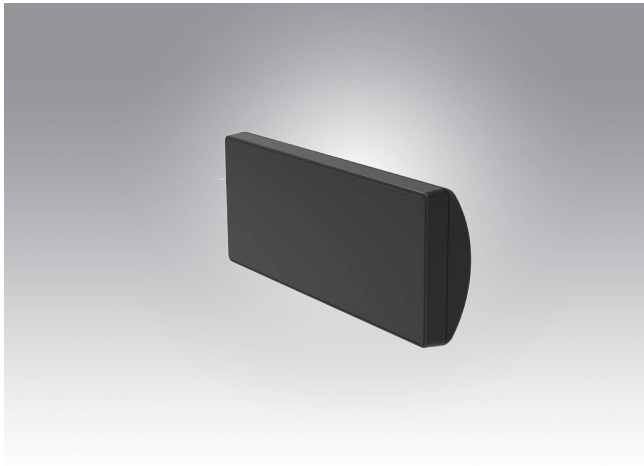

Specifications

Interface	COM
Number of Characters	40(20 columns x 2 lines)
Brightness	350~700cd/m2
Connection	Direct connection, Baud rate: 9600 or 19200bps
Language	USA,France,Germany,U.K.,Sweden,Denmark I & II, Italy, Spain, Norway,Japan,Slavonic,Russia, Greek,Czech,Latvian
Commands Mode	EPSON POS D101(default),AEDEX,UTC/S,UTC/P, ADM788,DSP800,CD5220,EMAX,LOGIC CONTROL
OS Support	Windows 7/8/10
Dimensions	218x89.6x52.2mm
Operating Temperature	0 ~ 40° C

Packing List


Description	Quantity
VFD Module Unit	1
Bracket	1
Screw	2

Ordering Information

P/N	Description
UPOS-P01-B110	VFD, rear mount for UPOS-211,black

UPOS-P05

Barcode scanner for UPOS-211

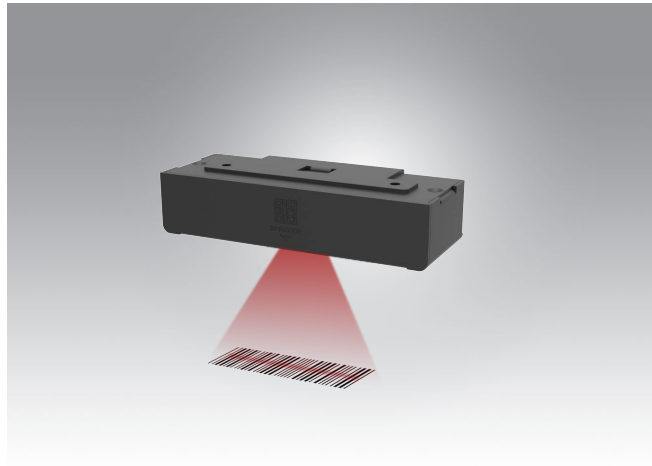

Specifications

Interface	USB	
Image Sensor	640x480 CMOS	
Symbolologies	2D	PDF417、 QR Code (QR1/2, Micro)、 Data Matrix (ECC200, ECC000, 050, 080, 100, 140)、 Chinese Sensible Code
	1D	Code128, UCC/EAN-128, AIM128, EAN-8, EAN-13, ISBN/ISSN, UPC-E, UPC-A, Interleaved 2 of 5, ITF-6, ITF-4, Matrix 2 of 5, Industrial 25, Standard 25, Code39, Codabar, Code 93, Code 11, Plessey, MSI-Plessey, GS1-DataBarTM(RSS), (RSS-14、 RSS-Limited、 RSS-Expand)
Resolution	≥ 5mil	
Light Source	Red LED 625±10 nm	
OS Support	Windows 7/8/10	
Dimensions	100x37.4x22mm	
Operating Temperature	0 ~ 40° C	

Packing List

Description	Quantity
Barcode Reader Unit Bracket	1
Screw	4

Ordering Information

P/N	Description
UPOS-P05-B110	2D Barcode scanner for UPOS-211,black

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[UPOS-P01-A102](#) [UPOS-P05-B110](#) [USC-P01-B110](#)