


UTC-300P-C

5M Camera Module for UTC-300 Series

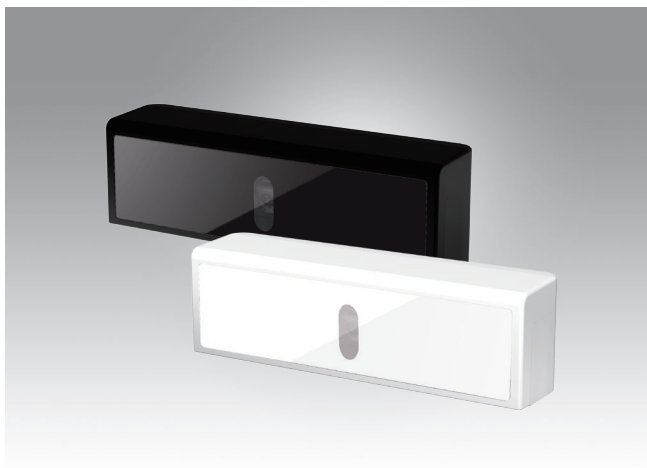

Specifications

Interface	USB
Cable Length	70cm
Image Resolution	2592 (H) x 1944 (V)
Focusing Range	10 cm~ ∞; Supports auto focus
Frame Rate	640 x 480 @ 30 fps max 1280 x 720 @ 30 fps max 1920 x 1080 @ 30 fps max 1600 x 1200 @ 15 fps max 2592 x 1944 @ 15 fps max
Video Format	MJPEG
OS Support	Windows XP/7/8
Dimensions	101 x 37 x 25 mm
Operating Temperature	0 ~ 40° C

Packing List

Description	Quantity
Camera Module Unit	1
Bracket	1
Screw	2
Installation Guide	1

Ordering Information

P/N	Description
UTC-300P-C10E	5MP camera module, White, for UTC-315
UTC-300P-C11E	5MP camera module, Black, for UTC-315
UTC-300P-C20E	5MP camera module, White, for UTC-318
UTC-300P-C21E	5MP camera module, Black, for UTC-318

UTC-300P-M

Magnetic Stripe Reader for UTC-300 Series



Specifications

Interface	USB
Cable Length	50cm
Track Configuration	TRACK 1 / IATA / 210 bpi / 79 Alphanumeric Characters TRACK 2 / ABA / 75 bpi / 40 Numeric Characters TRACK 3 / Thrift / 210 bpi / 107 Numeric Characters
Card Standard	ANSI/ISO Standards 7810, 7811-1-6, 7813
Read Speed	3 ips to 60 ips (7 cm/s to 150 cm/s)
Magnetic Head Life	1,000,000 times (ISO test standard)
OS Support	Windows XP/7/8 (Supports OPOS & JPOS Drivers)
Dimensions	101 x 37 x 25 mm
Operating Temperature	0 ~ 40° C

Packing List

Description	Quantity
Magnetic Stripe Reader Unit	1
Bracket	1
Screw	2
Installation Guide	1

Ordering Information

P/N	Description
UTC-300P-M10E	Magnet Strip Reader, White, for UTC-315
UTC-300P-M11E	Magnet Strip Reader, Black, for UTC-315
UTC-300P-M20E	Magnet Strip Reader, White, for UTC-318
UTC-300P-M21E	Magnet Strip Reader, Black, for UTC-318

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[UTC-300P-C20E](#) [UTC-300P-M20E](#) [UTC-300P-M10E](#) [UTC-300P-C10E](#) [UTC-300P-M21E](#) [UTC-300P-C21E](#) [UTC-300P-C11E](#) [UTC-300P-M11E](#)